




## Caravel AC (AC Fan)



COMAIR ROTRON PART NUMBER: **020189**  
 COMAIR ROTRON MODEL NUMBER: **CLE2T2**


MOTOR	
Rated Voltage:	115
Operating Voltage Range:	
Running Current: 50Hz   60Hz (amps)	0.48   0.5
Locked Rotor Current: (amps)	0.7
Rated Power: 50Hz   60Hz (watts)	34   0
Nominal Speed: 50Hz   60Hz (rpm)	1400   1650

MECHANICAL	
Dimensions:	254mm x 88.9mm (10.0in x 3.50in)
Bearing Type:	Ball
Motor Base:	Aluminum
Propeller:	Polycarbonate, UL94V-0, Black

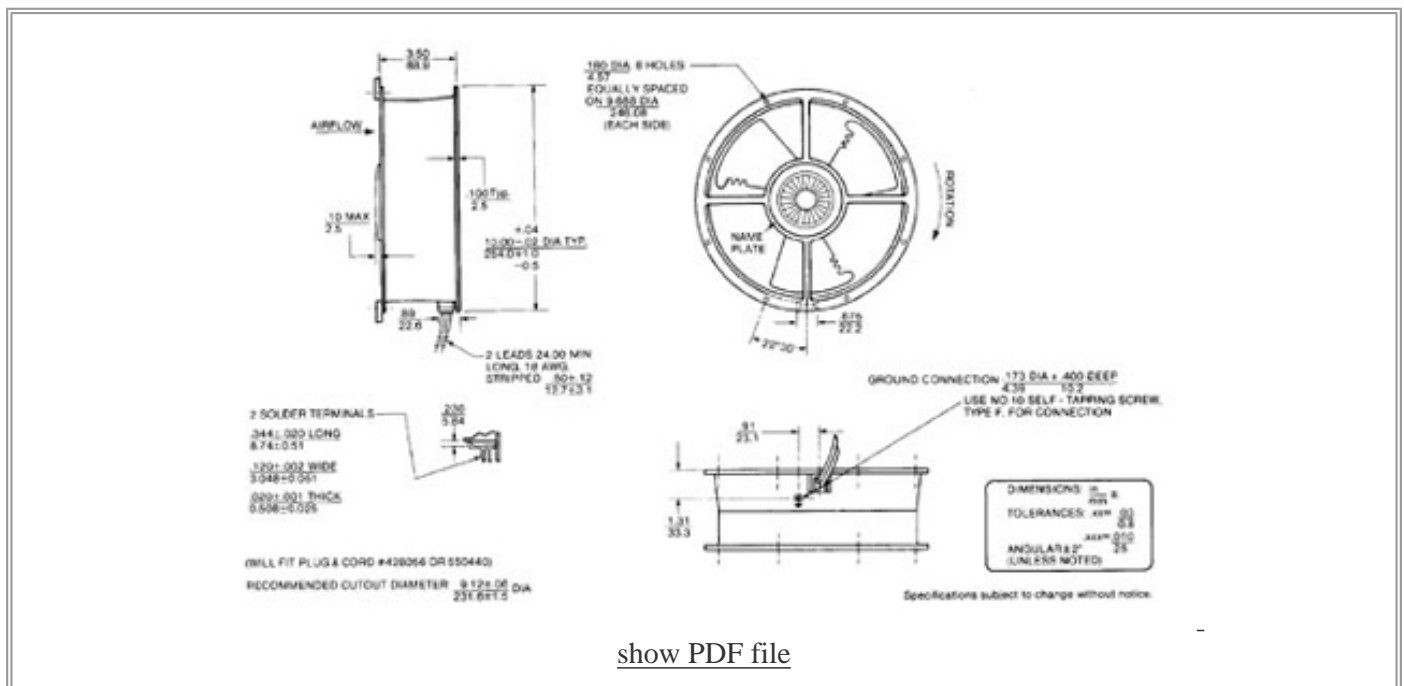

[show PDF file](#)

### NOTES

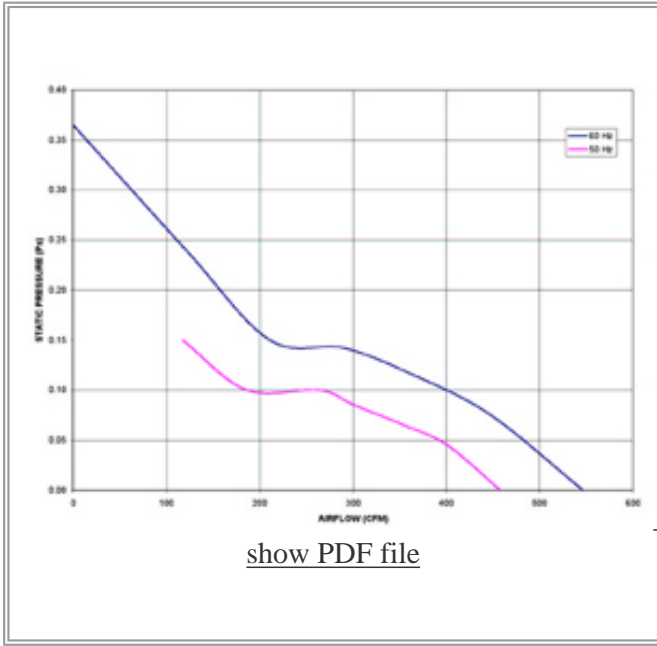

PERFORMANCE CHARACTERISTICS	
Air Flow: (CFM)	455/550
Static Pressure:	.287/.365

TERMINATION	
Leadwires:	Terminals

SAFETY				
				

All product names are used under license and are trademarks or registered trademarks of Comair Rotron, Inc.

[New Search](#)