

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0430300002

Status:


Active

Overview:

Micro-Fit 3.0™ Connectors

Description:

Micro-Fit 3.0™ Crimp Terminal, Female, with Select Gold (Au) Plated Phosphor Bronze Contact, 20-24 AWG, Reel

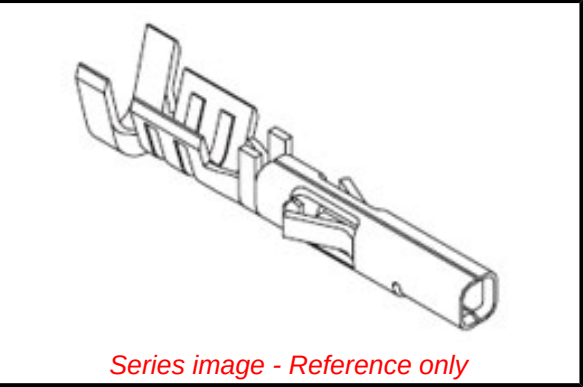

Documents:	
3D Model	Test Summary TS-43045-002 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-43045 (PDF)	Product Literature (PDF)

General	
Product Family	Crimp Terminals
Series	43030
Application	Power
Crimp Quality Equipment	Yes
Overview	Micro-Fit 3.0™ Connectors
Packaging Alternative	43030-0008 (Loose)
Product Literature Order No	987650-5984
Product Name	Micro-Fit 3.0™
UPC	800753683662
Physical	
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Net Weight	0.062/g
Packaging Type	Reel
Plating min - Mating	0.381µm
Plating min - Termination	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.85mm max.
Wire Size AWG	20, 22, 24
Wire Size mm²	N/A
Electrical	
Current - Maximum per Contact	5.0A
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-43045, RPS-43045-003, RPS-43045-004
Sales Drawing	SD-43030-****
Test Summary	TS-43045-002

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

No -ED/39/2015 (15

June 2015)

Halogen-Free

Status

Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

43030 Series

Mates With

43031 Micro-Fit 3.0™ Male Crimp Terminals

Use With

43025 , 43645 Micro-Fit 3.0™ Receptacle Housings, 44133 Micro-Fit BMI™ Panel Mount Receptacle Housings

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Insertion Tool for Crimp Terminal	0638120800
Extraction Tool	0011030043

T2 Terminator™	<u>0639118900</u>
for insulation OD	
0.91-1.09mm - 20-24	
AWG	
T2 Terminator™	<u>0639118800</u>
for insulation OD	
1.10-1.30mm - 20-24	
AWG	
Hand Crimp Tool	<u>0638190000</u>
T2 Terminator™	<u>0639104500</u>
for insulation OD	
1.30-1.85mm - 20-24	
AWG	
FineAdjust™	<u>0639004500</u>
Applicator for	
Insulation OD	
1.30-1.85mm, 20-24	
AWG Wire	
FineAdjust™	<u>0639018800</u>
Applicator for	
Insulation OD	
1.10-1.30mm - 20-24	
AWG	
FineAdjust™	<u>0639018900</u>
Applicator for	
Insulation OD	
0.91-1.09mm - 20-24	
AWG	
Japan	
Description	Product #
Applicator for M211A	<u>0572983000</u>
Bench Press, 20-30	
AWG Wire	

This document was generated on 11/30/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION