


ExpressCage MB322SP-B

ICY DOCK
www.icydock.com

2x 2.5" SATA/SAS HDD/SSD to 5.25" Bay
Mobile Rack w/ 3.5" HDD/Device Slot

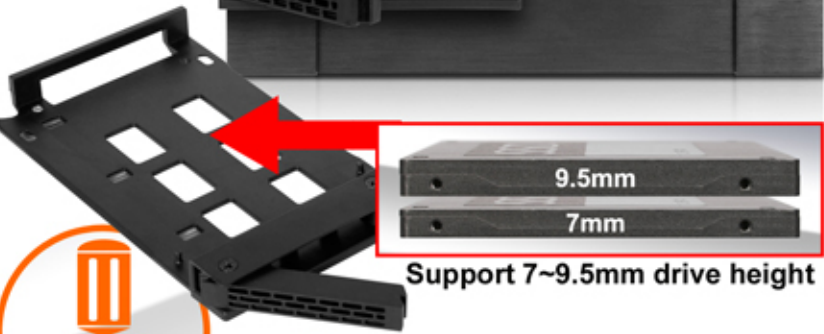

Dual 2.5" HDD/SSD Hot-Swap Bay
Supports 7mm to 9.5mm HDD heights



5.25" BAY



3.5" Device Front Bay
Supports 3.5" devices or 3.5" hard drive w/ detachable dust cover



3.5" Device



3.5" HDD

Detachable Dust Cover



FRONT



REAR

← Detachable Dust Cover

ExpressCage MB322SP-B Features & Specs

- Compatible with any standard 5.25" device bay
- Fits 2x 2.5" SATA/SAS HDD/SSD and 1x 3.5" HDD/Device
- Supports 2.5" SATA/SAS HDD/SSD of 7mm & 9.5mm height
- Supports SATA 6Gbps or SAS single channel (requires SAS host)
- Active Power Technology (APT) - only powers up if there is drive installed in the drive bay
- Soft blue indicator LED provided for each 2.5" HDD/SSD bay
- Detachable dust cover for 3.5" slot to keep debris from entering your system
- Enhanced tray and metal housing with for maximum durability
- ExpressTray Mini system for tool-less and easy 2.5" HDD/SSD installation
- Numerous ventilated slots for enhanced cooling
- Locking latch design for 7 pin SATA connectors
- Compatible with our lineup of 3.5" mobile racks like the MB991SK-B and MB992SK-B
- Designed for power users and system builder applications, mainly space saving and hot swap usage and for 2.5" HDD or SSD

Model Number	MB322SP-B
Color	Black
Host Interface	2 x 7pin SATA
Drive Fit	1 x 3.5" device or 1 x 3.5" hard drive 2 x 2.5" SATA or SAS (single channel) HDD/SSD
Compatible 2.5" Drive Heights	7mm, 9.5mm
Device Fit	Single 5.25" half height device bay
Transfer Rate	Up to 6 Gb/sec. (depending on hard drive speed)
Power Input	Single 15pin SATA power port
Insert & Extract connection Via	Direct SAS/ SATA hard drive connection
Structure	Plastic and metal
Power Indicator	Solid blue LED
HDD Access Indicator	Blinking blue LED
Dimension (L x W x H)	145.8 x 41.3 x 151.1mm
Weight	346.3g
Package Contents	Device, user manual, screws