

IEC
LOCK+
REWIREABLE

THE ORIGINAL & PATENTED RETROFIT SOLUTION ...NOW COMES IN A REWIREABLE VERSION!

Guards against accidental disconnection of
Computers, PDU's, Servers and most Network Devices.

NEW

**WORLD'S
FIRST**

**LOCKING REWIREABLE
C13 IEC CONNECTOR**

**Connector cannot be accidentally pulled or
vibrated out of 'ANY STANDARD' C14 IEC inlet**

- Requires no other equipment or special inlets to secure it
- **Rewireable** - offering total flexibility when assembling cables
- Can be retrofitted
- **LSZH** - Low smoke zero halogen

SLIM DESIGN • EASY TO REMOVE • EASY TO IDENTIFY







**LSZH (LOW SMOKE ZERO HALOGEN) CRUCIAL FOR CRITICAL APPLICATIONS IN
MILITARY, BROADCAST, TRANSPORTATION, DATA CENTRES SECTORS ETC.**

PA130100BK

Rewireable IEC Lock®+ Low Smoke Zero Halogen Appliance Connector

SLIM DESIGN • EASY TO REMOVE
• EASY TO IDENTIFY •

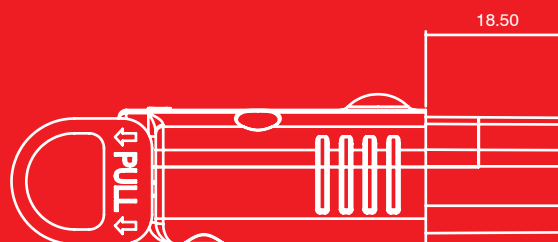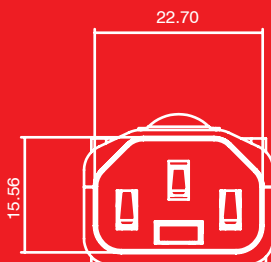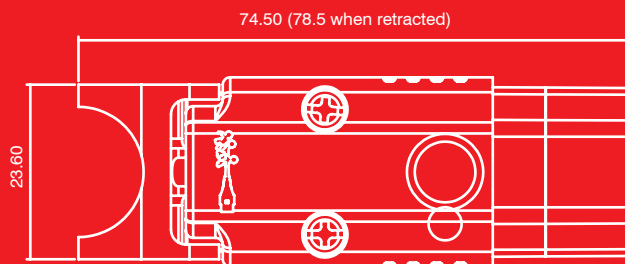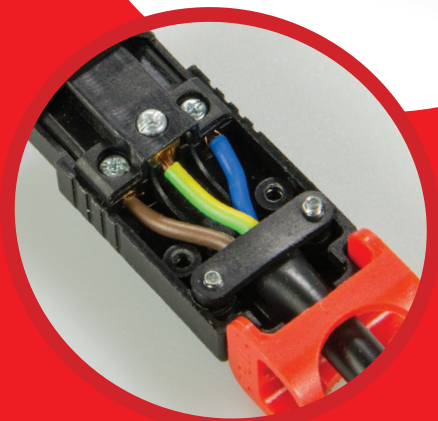

THE ORIGINAL & PATENTED RETROFIT SOLUTION
...NOW COMES IN A REWIREABLE VERSION!

Rating

10A Max / 250V~ (Europe)
15A Max / 250V~ (USA)

Test Information

Test Body: KEMA, UL,

Test Standard: KEMA-KEUR:

Certified: EN 60320-1:2001+A1:2007
UL 60320-1 / CSA C22.2 No. 60320-1

Patents:

EU Patent No. EP14594121

Cable Size

3C x 0.75mm²
3C x 1.00mm²
3C x 1.25mm²
3C x 1.50mm² Max
3C x 14-18awg