

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190730019

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp™ Ring Tongue Terminal for 18 to 22 AWG Wire, Stud Size 10 (M5), Length 22.00mm, Mylar Tape Carrier

Documents:


3D Model

Drawing (PDF)

Product Specification PS-19902-011 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19073
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	Avikrimp™
Type	Ring
UPC	800753075085
Physical	
Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	0.771/g
Packaging Type	Adhesive Tape on Reel
Stud Size	10 (M5)
Wire Insulation Diameter	3.60mm max.
Wire Size AWG	18, 20, 22
Wire Size mm²	0.35-0.80
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Old Part Number	AA-821-10T
Reference - Drawing Numbers	
Product Specification	PS-19902-011
Sales Drawing	SD-19073-002

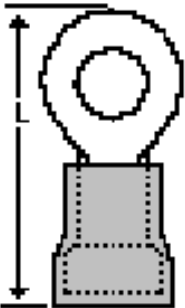

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Contains SVHC(2014

December 17): No

Halogen-Free

Status

Not Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

19073 Series

Application Tooling | FAQ

Tooling specifications and manuals are

found by selecting the products below.

Crimp Height Specifications are then

contained in the Application Tooling

Specification document.

Global

Description

Product #

ATP Crimp Dies

0192880023

for the Tape Crimp

Module and ATP-101

& 301 Press

Mini-Mac™

0638851300

Applicator

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION