


DIN 41612

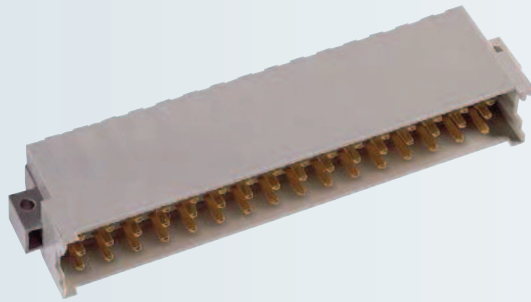

Type F Male Connector



Type: Male connector 90° with 3 rows

Termination: Solder

Number of contacts: 32, 48

Pitch: 5.08 mm x 3.81 mm


Operational current: 5.6 A

Packaging: Box

Standard: IEC 60603-2



Technical Specifications on page 36

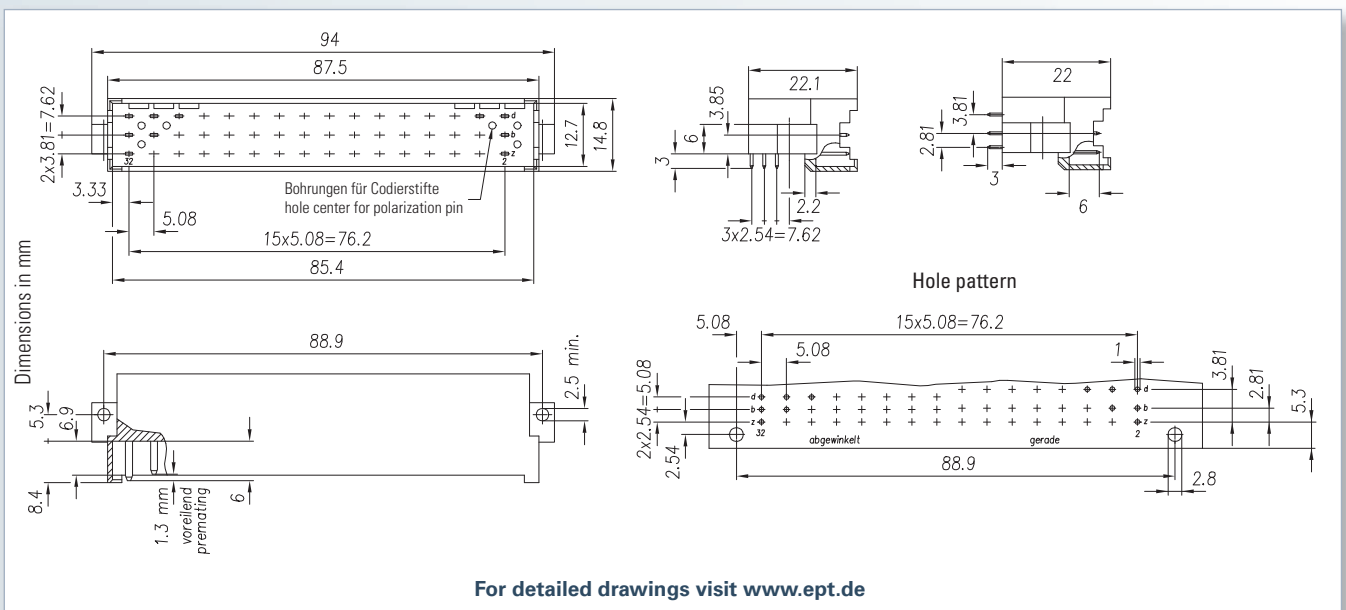

Accessories

- Coding p. 132

Mating connector / Application:



Type F Female connector (p. 96)



Type F low profile Female connector (p. 98)



Solder - Performance level II •••

No. of contacts	Contact arrangement	Termination length		
		L 3 mm 3 rows below	L 3 mm 3 rows sideways	L 3 mm 2 rows below
Artikelnummer				
32		-	109-40025	109-40024
32		109-40014	109-40015	-
48		109-40064	109-40065	-

On request

- performance level I + III or customized
- special contact length
- also in THTR
- Board-Lock p. 131
- contact arrangement