

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0008700043](#)
Status: **Active**
Description: 4.80mm Pitch Crimp Terminal, Male, Bag

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-5025-002 \(PDF\)](#)
[Product Specification PS-5025-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Crimp Terminals
 Series [5006](#)
 Application Power
 Crimp Quality Equipment Yes
 Product Name N/A
 UPC 800753614345

Physical


Gender Male
 Material - Metal Brass
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 137.700/mg
 Packaging Type Bag
 Plating min - Mating 0.889µm
 Plating min - Termination 0.889µm
 Termination Interface: Style Crimp or Compression
 Wire Insulation Diameter 1.30-3.00mm
 Wire Size AWG 18, 20, 22, 24
 Wire Size mm² N/A

Material Info

Old Part Number 5006TL

Reference - Drawing Numbers

Product Specification PS-5025-001, PS-5025-002, RPS-5025-003
 Sales Drawing SD-5006*

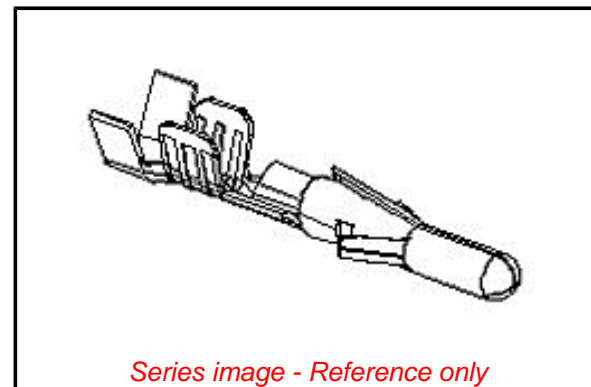

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/79/2015 (17
 December 2015)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

China RoHS

Green Image

Not Relevant

Search Parts in this Series

[5006](#) Series

Mates With

[5005](#)

Use With

[5025](#) Plug

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Hand Crimp Tool for [0638191300](#)
 Standard 1.57mm
 Pin and Socket

Crimp Terminals,
18-24 AWG
Manual Extraction Tool

0011030002

Japan

Description

Product #

Hand Insertion Tool 0011260005

This document was generated on 02/29/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION