

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0022552103**
Status: **Active**
Overview: SL™ Modular Connectors
Description: 2.54mm Pitch SL™ Crimp Housing, Dual Row, Version C, Back Ribs, 10 Circuits

Documents:

3D Model	Product Specification PS-70400 (PDF)
Drawing (PDF)	Test Summary TS-70058-001 (PDF)
Product Specification PS-70058 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	<u>70450</u>
Application	Signal, Wire-to-Board
Comments	Version C
Overview	<u>SL™ Modular Connectors</u>
Product Name	SL™
UPC	800755673852

Physical

Breakaway	No
Circuits (maximum)	10
Color - Resin	Black
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Polyester
Net Weight	0.960/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40°C to +105°C

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Old Part Number	70450-0103
-----------------	------------

Reference - Drawing Numbers

Product Specification	PS-70058, PS-70400
Sales Drawing	SD-70450-0100-0125
Test Summary	TS-70058-001

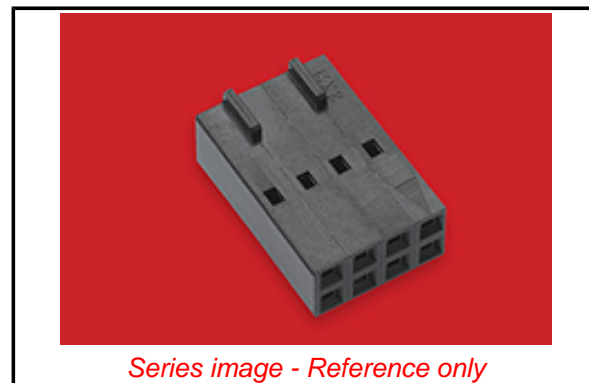

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/79/2015 (17
December 2015)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

70450 Series

Mates With

2.54mm Pitch C-Grid® Header 70229 ,
70280 , 70246 , 70247

Use With

70058 , 71851