

## Specifications


	ABI-048-RC
Rated voltage	6VDC
Operating voltage	4~8VDC
Rated current*	≤33mA
Sound output at 30cm*	≥95dB
Resonant frequency	400±100Hz
Tone	Single
Operating temperature	-20~+60°C
Storage temperature	-30~+70°C
Housing Material	ABS (White)
Lead Material	UL1007 AWG28
Weight	17g

\* Value applying at rated voltage (DC)

## Features

- ROHS compliant
- White in colour
- Fitted with flying leads
- Panel or base flange mounted
- Housing material: ABS

All data at 25°C unless otherwise specified

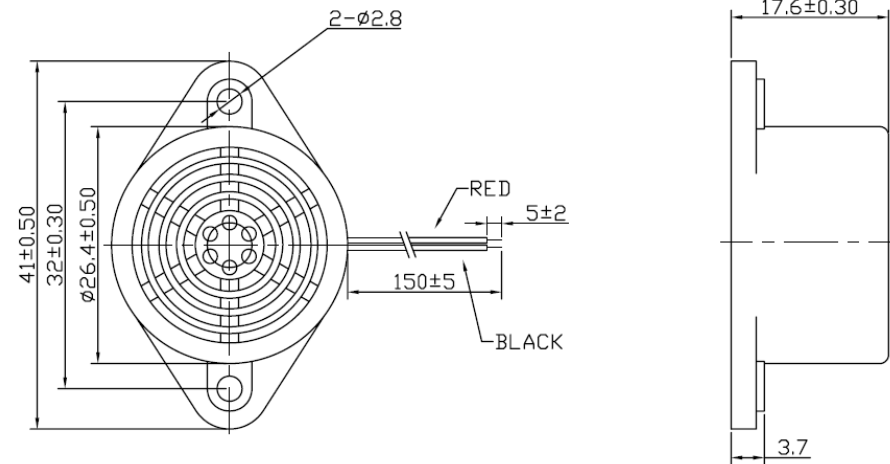

**Dimensions** Unit: mm Tolerance: ±0.5mm



ALAN BUTCHER COMPONENTS LTD

**Alan Butcher Components Ltd**

Unit 1 Beechwood Clump Farm Industrial Estate Tin Pot Lane Blandford Dorset DT11 7TD

Telephone 01258 456360 Facsimile 01258 459194 Email sales@abcomponents.co.uk

[www.abcomponents.co.uk](http://www.abcomponents.co.uk)



BS EN ISO 9001 Certification No 5239