


Capacitor, Tantalum, 3.3 uF, +/-10% Tol, 10 V

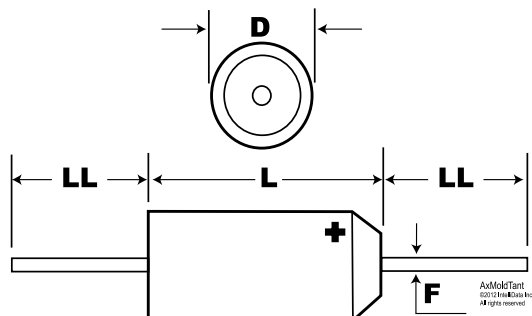

## Dimensions (mm)

Symbol	Dimension	Tolerance
D	2.41	MAX
L	6.6	MAX
F	0.51	+/-0.05
LL	38.1	+/-6.35

## Packaging Specifications

Package Kind:	Bulk
Package Type:	Bag
Package Quantity:	300

## General Information

Supplier:	KEMET
Application:	General Purpose
Body Type:	Axial
Lead Type:	Un-insulated Wire
Termination Type:	Tin (Sn)
RoHS:	Yes

## Specifications

Capacitance:	3.3 uF
Tolerance:	+/-10%
Voltage:	10 VDC (85C)
Voltage:	9 VDC (125C Surge)
Voltage:	0.1 V (125C Reverse)
Temperature Range:	-55/+125C
Resistance/ESR:	10 Ohms (100kHz)
Leakage Current:	0.5 uA
Dissipation Factor:	4%