

France, Belgium, Switzerland
Ferrania France SAS
Immeuble "Le Jules César"
12 Chaussée Jules César
BP 264 Osny
95523 Cergy Pontoise Cédex - France
Tel: +33 1 34 24 53 00
Fax: +33 1 34 24 53 10 (Service Commandes)
Fax: +33 1 34 24 53 20 (Service Commercial)
ferraniafrance@ferraniait.com

Germany, Austria, Netherlands
Ferrania Deutschland GmbH
Hammfelddamm 10
41460 Neuss - Germany
Tel: +49 21 31 124660
Fax: +49 21 31 124666
ferraniagermany@ferraniait.com

Italy
Ferrania S.p.A.
Uffici Commerciali: Centro Direzionale
Via Rivoltana 2/d
20090 Segrate (MI) - Italy
Tel: +39 02 753918.1
Fax: +39 02 753918.845
ferraniaitalia@ferraniait.com

Spain & Portugal
Ferrania Ibérica SA
C/Isa Graciosa, 1 - Edificio Ancora
28700 San Sebastián de los Reyes
(Madrid) - Spain
Tel: +34 902 160 519
Fax: +34 916 638 680
ferraniaiberica@ferraniait.com

UK, Ireland, Sweden, Denmark, Norway, Finland
Ferrania UK Limited
Amber House
Market Street
Bracknell
Berkshire RG12 1JB UK - England
Tel: +44 (0) 1344 312100
Fax: +44 (0) 1344 489364
uksales@ferraniait.com

USA
Ferrania USA, Inc.
Sales, Marketing and Technical Service Offices:
6063 Hudson Road, Suite 121
Woodbury, MN 55125
USA
Tel: + 1 888 846 2846
Fax: + 1 651 704 4128

All other countries (Export Division)
Ferrania S.p.A.
Viale della Libertà, 57
Frazione Ferrania
I 17014 Cairo Montenotte (SV) - Italy
Tel: +39 019522 4336/4442/4236
Fax: +39 019522 4384
photoexport@ferraniait.com

E-mail: optijet@ferraniait.com
Web site: www.ferraniait.com/optijet

2003©M.A.D.

KK005400019

July 2003

Ferrania
Imaging Technologies

80 years of innovation in photography

OptiJet
inkjet media

**No limit to your
imagination**

A wide range to meet every requirement



Ferrania
Imaging Technologies


Since 1923, Ferrania Imaging Technologies has researched, developed, produced and supplied products and services to imaging and photographic markets throughout the world.

Ferrania has utilised its skills and knowledge acquired from the photographic film sector, to develop a range of high quality paper for inkjet printers that cover all application requirements, with a particular focus on photographic papers.

OptiJet
inkjet media

In the OptiJet™ range, created by Ferrania Imaging Technologies, the photographic paper is designed to achieve the best possible image quality with any inkjet printers. The Advanced Multilayer Technology controls the ink absorption and assures glossy and saturated colours.

MULTILAYER STRUCTURE

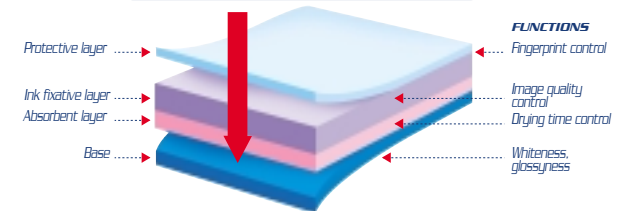

Total compatibility

Excellent results on any kind of inkjet printers:
Epson, Canon, HP, Lexmark...

Excellent colour brilliance

Accurate colour reproduction

with both original cartridges and OptiJet™,
the convenient compatible cartridges

High resolution print

Sharp images

Wide media options

A wide range of supports and formats for any kind of requirements

Simplicity and functionality

To ensure the best results are obtained, easy to follow printing
set up instructions are included in every pack



PHOTO

PROFESSIONAL

Glossy & Satin Photo Paper

Professional Glossy & Satin Photo Paper

Print your favourite photos on this paper which is designed to obtain the brightest colours, sharp images and text without any imperfections.



- Weight 260 grams
- Instant drying and water resistant
- Same appearance and feel of a conventional photo
- Printable up to 2880/5760 dpi
- Glossy or Satin finish
- Compatible also with pigmented inks

Instant drying

Ideal for:

- Photographs
- Enlargements
- Photographic Film-tests
- Photographs for framing

Professional Glossy Photo Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	260	15
10x15 - 4" x 6"	102 x 152 mm	260	20
A3	297 x 420 mm	260	15
A3+	330 x 483 mm	260	50

Professional Satin Photo Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	260	15
A3	297 x 420 mm	260	15
A3+	330 x 483 mm	260	50



PHOTO

PHOTO PAPER

Glossy Premium Weight

Photo Paper Glossy Premium Weight

Capture your favourite memories on this versatile paper. Print them on a glossy paper to produce brilliant colours which won't fade over time.



- Weight 230 grams
- Detailed reproduction, photograde quality and excellent light fading robustness
- High resolution up to 2880/5670 dpi
- Sharp images.

Long lasting images

Ideal for:

- Photographs
- Enlargements
- Calendars and Posters
- Covers
- Colour Tests
- Brochures

Photo Paper Glossy Premium Weight

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	230	10
A4	210 x 297 mm	230	20
A4	210 x 297 mm	230	50
A6	105 x 148 mm	230	25
A3	297 x 420 mm	230	20
A3+	330 x 483 mm	230	50
A2	420 x 594 mm	230	50



PHOTO

PHOTO QUALITY

Glossy Paper

Photo Quality Glossy Paper

Ideal for everyday use: brilliant colours on a glossy photo quality paper.



- Instant drying
- High resolution, best results up to 1440 dpi
- Brilliant colours.

Instant drying

Ideal for:

- Photographs
- Pictures
- Web pages
- Brochures

Photo Quality Glossy Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	155	25



MULTI-USE PHOTO
GLOSSY MATTE
Double Sided Photo Paper

Glossy Matte Double Sided Photo Paper

Create your professional photo album or flyers, printing brilliant colours on this two sided paper. Glossy side for images and photos, matte side for text and graphics.



- Double Sided: Glossy/Matte
- Instant drying
- High resolution, best results up to 1440 dpi

Double sided

Ideal for:

- Photo Album
- Brochures
- Flyers
- Publications

Glossy Matte Double Sided Photo Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	185	20



MULTI-USE PHOTO
MATTE PAPER
High Resolution

High Resolution Matte Paper

High resolution quality prints with a matte finish, ideal for precise text and graphic images. This photographic size is suitable for instant printing of all your digital photos, greetings cards and postcards.



- Photo quality
- Precision in detail
- Versatile, light and foldable
- Saturated colour
- Matte surface
- Quick drying



Photo quality

Ideal for:

- Photos with matte finish
- Corporate presentation
- Circular and professional letters
- Charts
- A6: Digital photos
- A6: Greetings cards and postcards

Matte Paper High Resolution

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	120	100
A6	105 x 148 mm	170	50
A3	297 x 420 mm	120	100
A3+	330 x 483 mm	120	100



MULTI-USE PHOTO
ADHESIVE
Photo Paper

Adhesive Photo Paper

Create, print and cut glossy adhesive images to personalise your own subjects. Communicate your creativity through images, designs and bright colour photographs.



- Excellent image definition
- Bright white and colours
- Water resistant and instant drying
- Flexible and light for easy cutting

Water resistant

Ideal for:

- Labels
- Plates
- Drawings and adhesive photos

Adhesive Photo Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	120	10



FILM

ULTRA GLOSSY

White Film

Ultra Glossy White Film

Transforms your professional presentations with high impact images.



Saturated colours and ultra glossy white
 Superior printing quality
 Ultra bright and sharp presentations

Excellent sharpness

Ideal for:

- Colour photographs
- Presentations
- Professional printing
- Covers
- Colour tests

Ultra Glossy White Film

Format	Size	Thickness μ	Packaging sheets
A4	210 x 297 mm	100	15



FINE ART

ART CANVAS

Painting Cotton

Art Canvas Painting Cotton

Realise art with your printer. Your favourite images, portraits and landscapes will look and feel like an original painting, perfect to frame!



Ideal for portraits and landscapes
 Quick drying
 High quality reproduction

Ideal from framing

Ideal for:

- Art reproduction
- Photographs
- Portraits

Art Canvas Painting Cotton

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	350	10
A3	297 x 420 mm	350	5

SPECIALITY MEDIA

CD LABEL & COVER Glossy Photo Quality



Glossy Photo Quality for CD Labels and Covers

Transform your CD's into a colourful and eye-catching collection. Your CD's will be immediately recognisable with adhesive labels and CD covers.

Design and print software available free on our website

Instant drying and water resistant

2 adhesive labels per A4 sheet.
Diameter sizes: outer 117 mm, inner 40 mm

Covers: Each pack contains front and back CD covers

Glossy photo paper

Ideal for:

- Adhesive labels for CD's
- CD covers

CD Label Glossy Photo Quality

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	110	20 (2 labels per sheet)

CD Cover Glossy Photo Quality

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	175	20 (1 front and 1 back per sheet)

SPECIALITY MEDIA

BUSINESS CARD Glossy Photo Quality



Business Card Glossy Photo Quality

Create photographic quality colour business cards. Advertise your initiatives in a brilliant and effective way.

Design and print software available free on our website

80 business cards

Heavy weight and smooth edges give a professional feel to your presentation card

Instant drying and water resistant

Cards size: 85 x 54 mm

Smooth edges
Not microperforated

Ideal for:

- Business cards
- Special event cards

Business Card Glossy Photo Quality

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	200	8 (10 cards per sheet)



SPECIALITY MEDIA

MOUSE PAD Glossy Photo Paper



Mouse Pad Glossy Photo Paper

Personalise your Mouse Pad with your own designs and images printed on a special glossy photo paper.

Design and print software available free from our website

Easy to use

No need for scissors, glue or ironing

Mouse Pad Size: 19 x 24 cm

Easy

Ideal for:

- Mouse Pad

Mouse Pad Glossy Photo Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	230	5

A wide range to meet every requirement

Professional Glossy Photo Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	260	15
10 x 15 - 4" x 6"	102 x 152 mm	260	20
A3	297 x 420 mm	260	15
A3+	330 x 483 mm	260	50

Professional Satin Photo Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	260	15
A3	297 x 420 mm	260	15
A3+	330 x 483 mm	260	50

Photo Paper Glossy Premium Weight

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	230	10
A4	210 x 297 mm	230	20
A4	210 x 297 mm	230	50
A6	105 x 148 mm	230	25
A3	297 x 420 mm	230	20
A3+	330 x 483 mm	230	50
A2	420 x 594 mm	230	50

Photo Quality Glossy Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	155	25

Glossy Matte Double Sided Photo Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	185	20

Matte Paper High Resolution

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	120	100
A6	105 x 148 mm	170	50
A3	297 x 420 mm	120	100
A3+	330 x 483 mm	120	100

Adhesive Photo Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	120	10

PHOTO

MULTI-USE PHOTO

Ultra Glossy White Film

Format	Size	Thickness μ m	Packaging sheets
A4	210 x 297 mm	100	15

Art Canvas Painting Cotton

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	350	10
A3	297 x 420 mm	350	5

CD Label Glossy Photo Quality

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	110	20 (2 labels per sheet)

CD Cover Glossy Photo Quality

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	175	20 (1 front and 1 back per sheet)

Business Card Glossy Photo Quality

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	200	8 (10 cards per sheet)

Mouse Pad Glossy Photo Paper

Format	Size	Weight g/m ²	Packaging sheets
A4	210 x 297 mm	230	5

OptiJet
inkjet media

FILM

FINE ART

SPECIALITY MEDIA