

Specifications: OTB-358 Series

Features:

- Thru-Panel Barrier Construction
- UL & CUL Recognized
- Cover Included
- M5 Screws
- High Current – Rated for 60A
- Accepts # 3 AWG Wire

Electrical:

Current: 60A @ 600V
 Wire Range: 3 - 10 AWG
 IR: >10 (500V DC)
 Operating temp: -40°C - +90°C

Materials:

Housing: PBT (UL 94V-O)
 Terminal: Brass Ni plated
 Screw: M5 Steel, Ni plated
 Positions Available: 2-15

Specifications: OTB-359 Series

Features:

- Thru-Panel Barrier Construction
- UL & CUL Recognized
- Cover Included
- M6 Screws
- High Current – Rated for 75A
- Accepts # 3 AWG Wire



Electrical:

Current: 75A @ 600V
 Wire Range: 3 - 10 AWG
 IR: >10 (500V DC)
 Operating temp: -40°C - +90°C

Materials:

Housing: PBT (UL 94V-O)
 Terminal: Brass Ni plated
 Screw: M6 Steel, Ni plated
 Positions Available: 2-15


60A 600V 16 mm (.629")

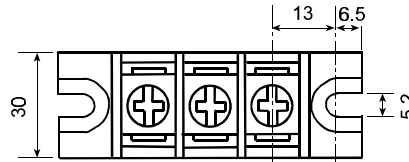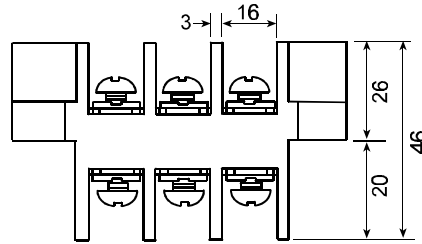



Dimensions

n= number of poles
 $L=(n \times 16) + 29$

Ordering Information

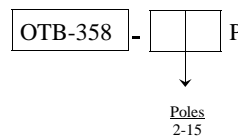

75A 600V 16 mm (.629")

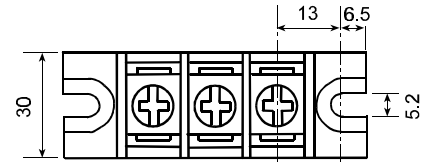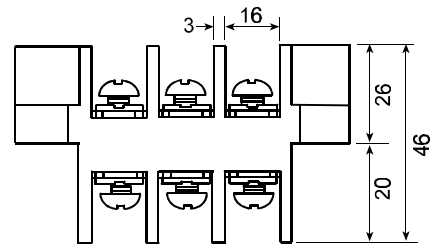

Dimensions

n= number of poles
 $L=(n \times 16) + 29$

Ordering Information

