

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190190027](#)
Status: **Active**
Overview: [Standard Quick-Disconnect Terminals](#)
Description: Avikrimp™ Quick Disconnect, Female, for 14-16 (2.00-1.30mm²) Wire, Box, Tab 4.75 x 0.51mm

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-014 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E79133

General

Product Family Quick Disconnects
Series [19019](#)
Crimp Quality Equipment Yes
Insulated Partial
MolexKits Yes
Overview [Standard Quick-Disconnect Terminals](#)
Product Name Avikrimp™
Type Quick Disconnect
UPC 800753038158

Physical

Barrel Type Closed
Color - Resin Blue
Flammability 94V-2
Gender Female
Glow-Wire Compliant No
Insulation Nylon (PA)
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.809/g
Orientation Straight
Packaging Type Bag
Polarized to Mating Part No
Tab Thickness 0.51mm
Tab Width 4.75mm
Temperature Range - Operating -65°C to +105°C
Wire Insulation Diameter 3.50mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Electrical

Voltage - Maximum 300V


Solder Process Data

Lead-freeProcess Capability N/A

Material Info

Old Part Number BB-8138

Reference - Drawing Numbers

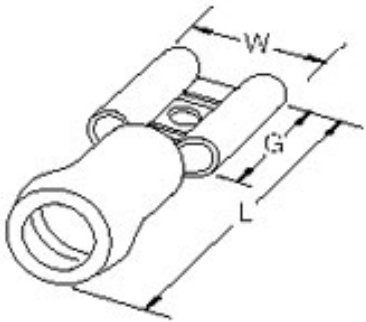

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/79/2015 (17
December 2015)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS
ELV

Green Image
Not Relevant

Search Parts in this Series

[19019](#) Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade™	0640010200
Hand Crimp Tool	
Crimp Head for the	0640050200
AT-200™ Pneumatic	
Hand Tool	

This document was generated on 03/04/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION