

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190690036](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite™ Ring Tongue Terminal for 18-22 AWG Wire

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)

Agency Certification
CSA LR18689
UL E32244


General
Product Family Ring and Spade Terminals
Series [19069](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name Krimptite™
Type Ring
UPC 800753067738

Physical
Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.485/g
Packaging Type Adhesive Tape on Reel
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 8 (M4)
Termination Interface: Style Crimp or Compression
Wire Size AWG 18, 20, 22
Wire Size mm² 0.35-0.80

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Old Part Number AA-121-08T

Reference - Drawing Numbers
Product Specification PS-19902-011
Sales Drawing SD-19069-004, SD-19069-020

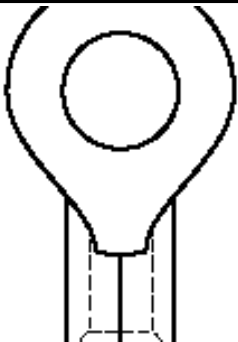

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per
-ED/79/2015 (17
December 2015)
Halogen-Free
Status
Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Green Image
ELV Not Relevant

Search Parts in this Series
[19069](#) Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Mini-Mac™	0638853800
Applicator	
ATP Crimp Dies	0190270034
for the Tape Crimp	
Module and ATP-101	
& 301 Press	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION