

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0511910300](#)
Status: **Active**
Overview: [Mini-Latch™ Wire-to-Board System](#)
Description: 2.50mm Pitch Wire-to-Wire and Wire-to-Board Receptacle Housing, with Guide Rails, 3 Circuits

Documents:

3D Model	Product Specification PS-51191-003 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-51191-002 (PDF)	

Agency Certification

UL	E29179
----	--------

General

Product Family	Crimp Housings
Series	51191
Application	Signal, Wire-to-Board, Wire-to-Wire
MolexKits	Yes
Overview	Mini-Latch™ Wire-to-Board System
Product Name	Mini-Latch™
UPC	800753327726


Physical

Circuits (maximum)	3
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Nylon
Net Weight	362.200/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Reference - Drawing Numbers

Product Specification	PS-51191-002, PS-51191-003, RPS-51191-007
Sales Drawing	SD-51191-004

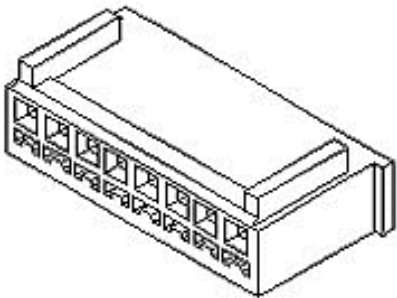

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/79/2015 (17
December 2015)

Halogen-Free

Status

Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant

Search Parts in this Series

[51191](#) Series

Mates With

[5045](#) Vertical Header . [5046](#) Right Angle
Header . [5240](#) Plug Housing

Use With

[50802](#) Crimp Terminal