


Product **Contacts: 8, female cable connector, cable outlet 3 -4 mm**

Area **Bayonet IP40 Series 710**
Article number **99 9480 100 08**


Illustration



Scale drawing

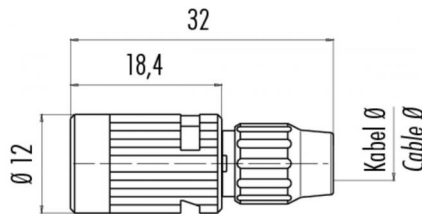

Contact Arrangement

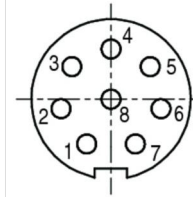

	X	Y
1	-0,90	-1,65
2	-1,85	-0,35
3	-1,45	1,20
4	0,00	1,85
5	1,45	1,20
6	1,85	-0,35
7	0,90	-1,65
8	0,00	0,00

You can find the item description on the next page.

Technical data

Common values

Connector Design	Cable socket
Connector locking system	Bayonet
Termination	solder
Wire gauge (mm)	0,14 mm ²
Wire gauge (AWG)	26
Cable outlet	3 - 4 mm
Upper temperature	85 °C
Lower temperature	-40 °C

Electrical values

Rated voltage	125
Rated impulse voltage	1500 V
Pollution degree	1
Overvoltage category	II
Material group	III
Rated current (40°C)	1 A
Volume resistivity	≤ 3 mΩ
EMV compliance	Shielding is not possible
Degree of protection	IP40
Mechanical operation	> 500 Mating cycles

Material

Material of contact	CuSn (Bronze)
Contact plating	Au (gold)
Material of contact body	PA (UL 94 V-0)

Product **Contacts: 8, female cable connector, cable outlet 3 -4 mm**

Area **Bayonet IP40 Series 710**
Article number **99 9480 100 08**

Item description

