


# 26 12 200 T



## Snipe Nose Side Cutting Pliers with tether attachment point with tether attachment point

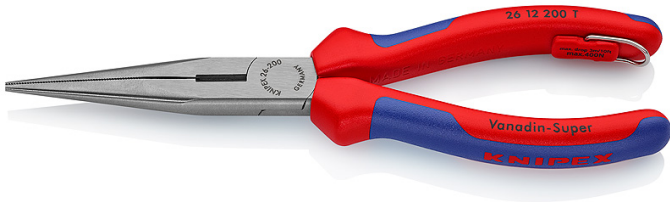

- Elastic tips: dimensionally stable even when twisted
- distortion-tolerant, elastic precision tips
- half-round, long, pointed jaws
- with cutting edges (hardness approx. 61 HRC) for soft, medium-hard and hard wire
- Vanadium electric steel; forged, oil-hardened
- Pliers with tether attachment point for mounting a fall protection



<b>Article No.</b>	26 12 200 T
<b>EAN</b>	4003773079989
<b>Head</b>	polished
<b>Handles</b>	with multi-component grips
<b>Style</b>	1
<b>Pliers</b>	
<b>medium hard wire Ø mm</b>	3,2
<b>hard wire Ø mm</b>	2,2
<b>L3 mm</b>	73,00
<b>T1 mm</b>	9,50
<b>W3 mm</b>	17,50
<b>W4 mm</b>	3,00
<b>T2 mm</b>	2,50
<b>Length mm</b>	200
<b>Net weight g</b>	200

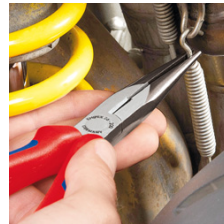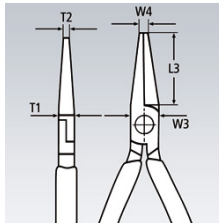

technical change and errors excepted