


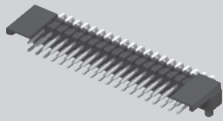


FSH-120-04-F-RA-SL



FSH-110-04-L-DH-SL



 SFMH-130-02-L-D-LC




SFMH-105-02-L-D-LC



SFMH-120-02-L-D

 FSH-120-04-F-DH



(1,27 mm) .050"

FSH, SFMH SERIES

HIGH RELIABLE HORIZONTAL SMT

FSH Mates with:
SFMH

Mates with:
FTSH, FSH

SPECIFICATIONS

For complete specifications see www.samtec.com?FSH or www.samtec.com?SFMH

FSH

Insulator Material:
Black Liquid Crystal Polymer
Terminal Material:
Phosphor Bronze
Plating:
Sn or Au over
50µ" (1,27 µm) Ni
Current Rating (FSH/SFMH):
2.6 A per pin
(1 pin powered per row)
Operating Temp Range:
-55°C to +125°C
RoHS Compliant:
Yes

Processing:

Lead-Free Solderable:
Yes
SMT Lead Coplanarity:
(0,15 mm) .006" max

SFMH

Same as FSH except:
Plating:
Au over 50µ" (1,27 µm) Ni
Contact Resistance:
15 mΩ
Insertion Depth:
(3,35 mm) .132" to
(4,57 mm) .180"
Insertion Force:
2.5 oz (0,69 N) average
Withdrawal Force:
2.0 oz (0,56 N) average
SMT Lead Coplanarity:
(0,10 mm) .004" max

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality



Note: Some sizes, styles and options are non-standard, non-returnable.

