



 
Schroff

EuropacPRO kit, light design, unshielded, for backplane mounting

Catalog Number: 24564-133

- Aluminum construction
- Subrack with side panel type L ("light") with firmly fixed 19" brackets
- Rear horizontal rails for backplane mounting with insulation strip
- Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1
- IP 20, in accordance with IEC 60529
- Modifications such as cutouts, different finishes or dimensions available
- Supplied as space-saving flat-pack
- Horizontal rail type "light"

Other Views



Description

Load:

Minimal

Shock/vibration:

Minimal

Design:

EuropacPRO, Light

EMC Shielding:

- Retrofitable
- Unshielded

Type:



Subrack Kit

Note:

Subrack is not prepared for shielding

Delivery Comprises:

Item	Quantity	Description
1	2	Side panel type L, Al, 2 mm, passivated, with built-in 19" support bracket
2a	2	Front horizontal rail (L-KD)
2b	2	Rear horizontal rail (L-ST)
3	4	Threaded inserts, front and rear (pre-fitted)
4	2	Insulation strip (pre-fitted)
5	1	Fixing materials kit, user manual

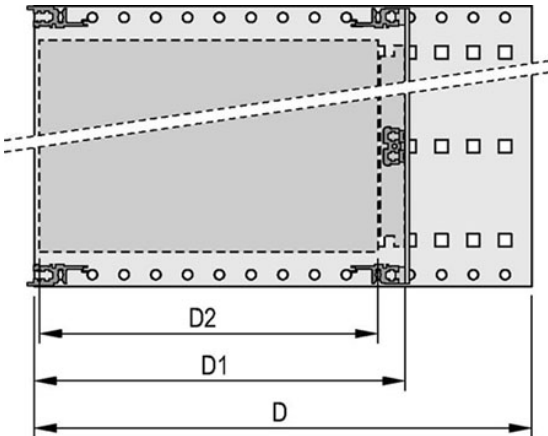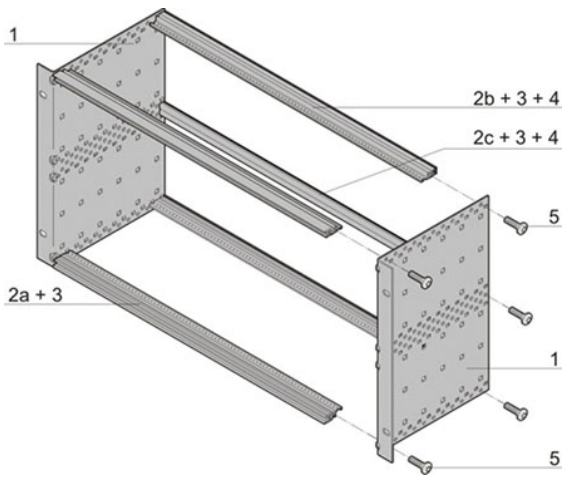

D = overall depth, D1 = insertion depth, D2 = board depth = D1 - 15 mm

 
 



 


Rear horizontal rail for backplane mounting with insulation strip

Technical Data

Catalog Number	24564-133
Depth mm	295.0
Height U	3.0
Width HP	84.0
Depth D mm	295.0
Depth D1 mm	175/235/295

Accessories

Item			
	Perforated rail for connector according to EN 60603-2 (DIN 41612), 84 HP, with thread M2.5, PU 4 pieces	20822-048	
	19" fixing material kit (screw, washer, nut), (8 × screws, 8 × plastic washers, 8 × cage nuts)	21100-435	
	ESD clip for guide rails, Spring steel, tin-plated, silver, PU 50 pieces	24560-255	
	Guide rails, standard, 160 mm deep, PBT, UL 94 V-0, red, groove width 2 mm, PU 10 pieces	24560-351	
	Guide rails, standard, 220 mm deep, PBT, UL 94 V-0, red, groove width 2 mm, PU 10 pieces	24560-353	
	Cover plate standard, 160 mm deep, Al, 1.2 mm, perforated, to push into light horizontal rail, PU 2 pieces	24561-051	
	Cover plate standard, 220 mm deep, Al, 1.2 mm, perforated, to push into light horizontal rail, PU 2 pieces	24561-052	