


Female Crimp Trio-Tek

- Part numbers are for housings only, see page 25 for Trio-Tek contacts.
- Contacts are rear-insertable.
- Crimp inspection window in housing.
- Mates with male connectors on pages 27 to 33.
- Ideal for volume applications.

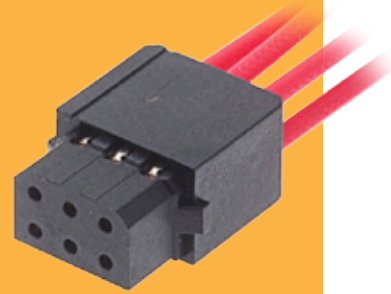

DATAMATE L-TEK

| SINGLE ROW | | CALCULATION | | DOUBLE ROW | | CALCULATION | | | | | |
|---|------------|-----------------|---|---|------------|---|------------------------------------|--------|--|----|---------|
| | | A | $B + 5.15$ | | | A | $B + 5.15$ | | | | |
| | | B | $(\text{Total no. of contacts} - 1) \times 2$ | | | B | $\text{Total no. of contacts} - 2$ | | | | |
| | | | | | | | | | | | |
| TOOLS | | | | WIRE STRIPPING DETAILS | | | | | | | |
| <p>Recommended Hand Crimp Tool – Z80-255</p> <p>See pages 87 to 89</p> <p>Instruction sheets available at www.harwin.com/downloads/instructions</p> | | | | | | | | | | | |
| HOW TO ORDER | | | | | | | | | | | |
| SERIES CODE | | M80 - 69 | | X XX | | 98 | | | | | |
| | | | | | | <table border="1"> <tr> <th colspan="2">FINISH</th> </tr> <tr> <td>98</td> <td>Housing </td> </tr> </table> | | FINISH | | 98 | Housing |
| FINISH | | | | | | | | | | | |
| 98 | Housing | | | | | | | | | | |
| TYPE | | | | TOTAL NO. OF CONTACTS | | | | | | | |
| 0 | Single Row | | | 02 to 07, 17 | Single Row | | | | | | |
| 1 | Double Row | | | 04, 06, 08, 10, 12, 14, 16, 18, 20, 26, 34, 44 | Double Row | | | | | | |

All dimensions in mm.