

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0009501061

Status:

Active

Overview:

SPOX™ Wire-to-Board Connectors

Description:

3.96mm Pitch SPOX™ Crimp Housing, Female, with Friction Ramp, 6 Circuits

Documents:

3D Model

Drawing (PDF)

Product Specification PS-5195-003 (PDF)

Product Specification PS-5195-005 (PDF)

Product Specification PS-5195-007 (PDF)

Product Specification PS-5273-003 (PDF)

Product Specification PS-5273-004 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

UL

LR19980

E29179

General

Product Family

Series

Application

Overview

Product Name

UPC

Crimp Housings

5195

Signal, Wire-to-Board

SPOX™ Wire-to-Board Connectors

SPOX™

800753534452

Physical

Circuits (maximum)

Color - Resin

Flammability

Gender

Glow-Wire Compliant

Material - Resin

Net Weight

Number of Rows

Packaging Type

Panel Mount

Pitch - Mating Interface

Pitch - Termination Interface

Stackable

Temperature Range - Operating

6

Natural

94V-2

Female

No

Nylon

1727.900/mg

1

Bag

No

3.96mm

3.96mm

No

-40°C to +105°C

Material Info

Old Part Number

5195-06


Reference - Drawing Numbers

Product Specification

PS-5195-003, PS-5195-005, PS-5195-007, PS-5273-003, PS-5273-004, RPS-5195-001, RPS-5195-002

Sales Drawing

SD-5195-N

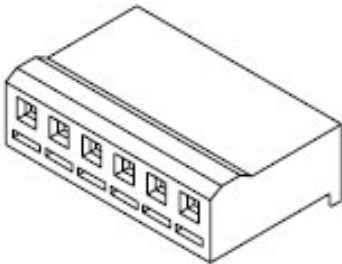

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per

-ED/79/2015 (17

December 2015)

Halogen-Free

Status

Low-Halogen

Need more information on product

environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any

non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

5195 Series

Mates With

5272 , 5273 , 5274 right angle PCB header, 5096 , 53405 , 5271

Use With

5194 , 5225

This document was generated on 03/29/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION