

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0349590381

Status:


Active

Overview:

Mini50™ Connection Systems

Description:

Mini50™ Unsealed Receptacle, 3 Rows, with CPA, 38 Circuits, Polarization Option B, Gray

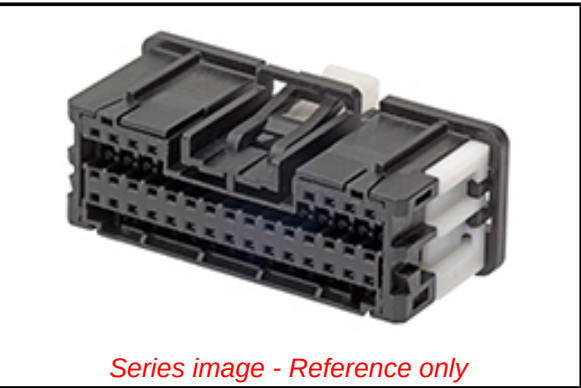

Documents:

3D Model

Drawing (PDF)

Product Specification PS-34959-001 (PDF)

Application Specification AS-34959-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	34959
Application	Power, Wire-to-Board
Overview	Mini50™ Connection Systems
Polarization	B
Product Name	Mini50™
UPC	887191704456
Physical	
Circuits (maximum)	38
Color - Resin	Gray
Gender	Receptacle
Glow-Wire Compliant	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	5.619/g
Number of Rows	3
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +105°C
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-34959-001
Product Specification	PS-34959-001
Sales Drawing	SD-34959-030

EU ELV

Compliant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -ED/79/2015 (17 December 2015)

Halogen-Free

Status

Not Relevant

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Relevant

ELV

Compliant

Search Parts in this Series

34959 Series

Mates With

Mini50™ Vertical Headers [34958](#) , Mini50™ Right-Angle Header [34961](#)

Use With

CTX50 Unsealed Terminals [560023](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION