

Key features:


- ❑ IP67 Ingress protection
- ❑ Momentary contact
- ❑ Anti-rotational mounting
- ❑ 20J Impact rating
- ❑ RoHS Compliant




IMPORTANT: This product is for use in 12Vdc and 24Vdc applications only and should only be installed by a qualified person

SR09744
DEF-0656-1-DR

Dimensions (mm) & Circuit:

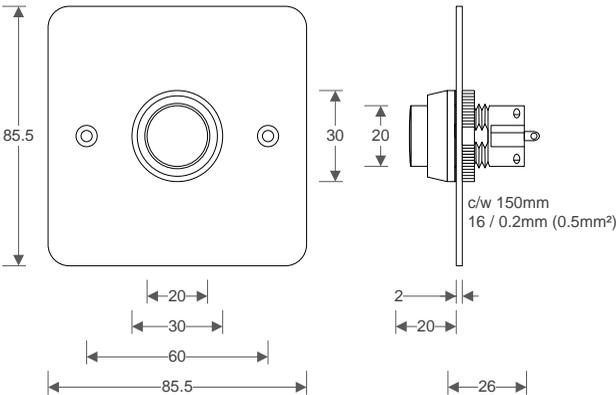

Form Z

 

Specification:

Mechanical:

Travel ——— 2.5mm
 Life (nom) ——— 2 x 10⁶ cycles
 Operating force — 7N
 Contact bounce — 5ms
 Panel ——— 2mm G304 ST/ST

Electrical:

Dielectric strength — 1000V
 Insulation resistance — 1GΩ
 Contact resistance — 25mΩ (initial)
 Current rating ——— 2A max @12-24Vdc
 Life ——— 100,000 cycles 20°C

Environmental & Physical:

Ingress protection — IP67
 Impact rating ——— 20J
 Shock ——— 50g
 Operating temp. — -40°C to +125°C *
 Body / actuator — Zinc alloy
 Terminal material — Tin plate nickel

Ordering information:

SR09744 Raised green push button, 1 gang, SSS, DOOR RELEASE



Online: cpc.co.uk
 Telephone: 08447 88 00 88
 Fax: 08447 88 00 89