

SMD terminal block with push-buttons in tape-and-reel packing; 1-pole; Pin spacing 4 mm / 0.157 in

Item No.: 2060-401/998-404



SMD terminal block with push-buttons in tape-and-reel packing; 1-pole; Pin spacing 4 mm / 0.157 in

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	2060-401/998-404
GTIN / EAN	4050821419440
Content	1
Order amount	1,500
Customer item number	

Notes

SMD terminal blocks with Push-in CAGE CLAMP® and push-buttonsHeight of just 4.5 mm minimizes on-board LED shadowingAvailable in tape-and-reel packaging for automated assemblyFor new designs please only use the new white version of 2060 series! [CLICK HERE!](#)

Technical data

Miscellaneous


No. of poles	1
Pin Spacing	4 mm (0.157 in %)
Total number of connection points	1
Total number of potentials	1
Color	white
Ratings according to 1	IEC/EN 60664-1
Overvoltage category EN 1	III


Technical data	
Pollution degree (1)	2
Rated voltage EN (1) [V]	160 [V]
Rated surge voltage (1) [kV]	2.5 [kV]
Nominal current [A]	9 [A]
Overvoltage category EN 2	II
Degree of pollution (2)	2
Rated voltage EN (2) [V]	320 [V]
Rated surge voltage (2) [kV]	2.5 [kV]
Nominal current (2) [A]	9 [A]
Overvoltage category EN 3	III
Degree of pollution (3)	3
Rated voltage EN (3) [V]	63 [V]
Rated surge voltage (3) [kV]	2.5 [kV]
Nominal current (3) [A]	9 [A]
Number of individual connection objects at the product	1
Connection technology (1)	Push-in CAGE CLAMP®
Solid sizes 1	0.2 ... 0.75 mm ² / 24 ... 18 AWG
Fine-stranded wires 1	0.2 ... 0.75 mm ² / 24 ... 18 AWG
Fine-stranded wires with insulated ferrule 1	0.25 ... 0.34 mm ² / ...
Fine-stranded wires with uninsulated ferrule 1	0.25 ... 0.34 mm ² / ...
Strip length 1	6 ... 7 mm / 0.24 ... 0.28 in
Solder pad dimensions [mm]	6 x 2 [mm]
Spulendurchmesser der Gurtverpackung [mm]	330 [mm]
Gurtbreite [mm]	24 [mm]
Material group	I
Insulating material	Polyphthalamid (PPA GF)
Flammability rating per UL 94	V0
Limit temperature range	-60 C ... 105 C
Contact material	Copper alloy
Contact plating	tin-plated
Fire load [MJ]	0.003 [MJ]
Weight [g]	0.525 [g]
Width	3.9 mm / 0.154 in
Height	4.5 mm / 0.177 in

Technical data	
Length	13.1 mm / 0.516 in

Images & drawings



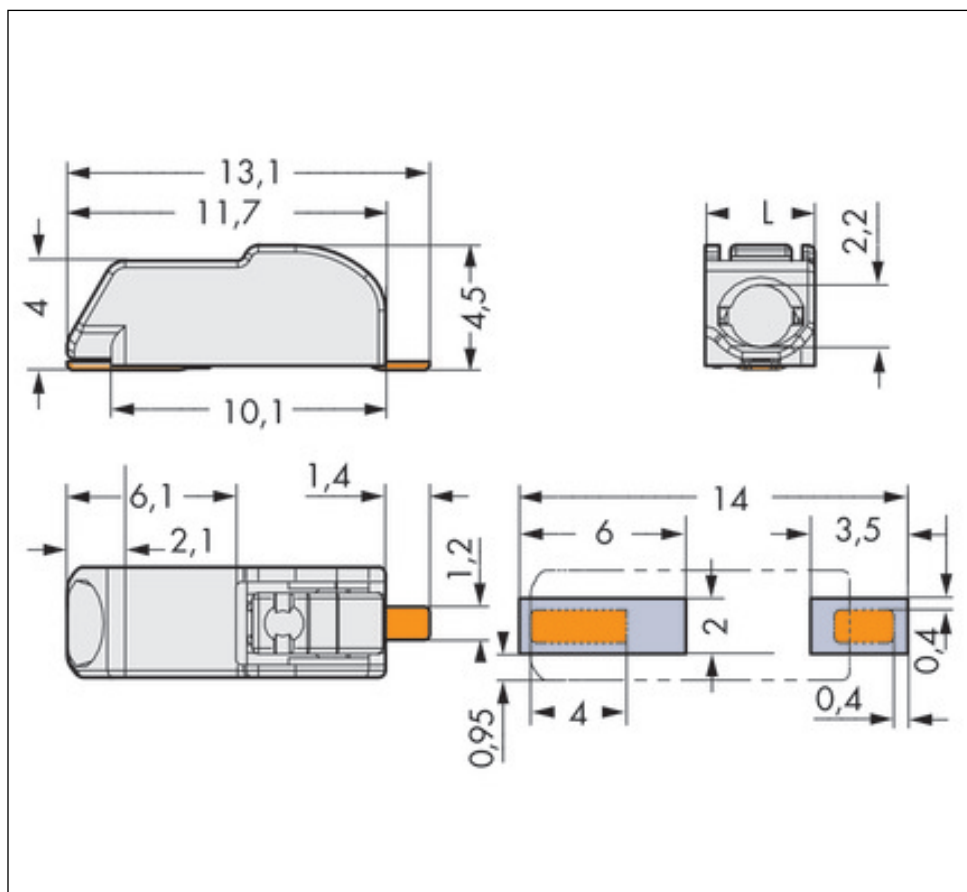

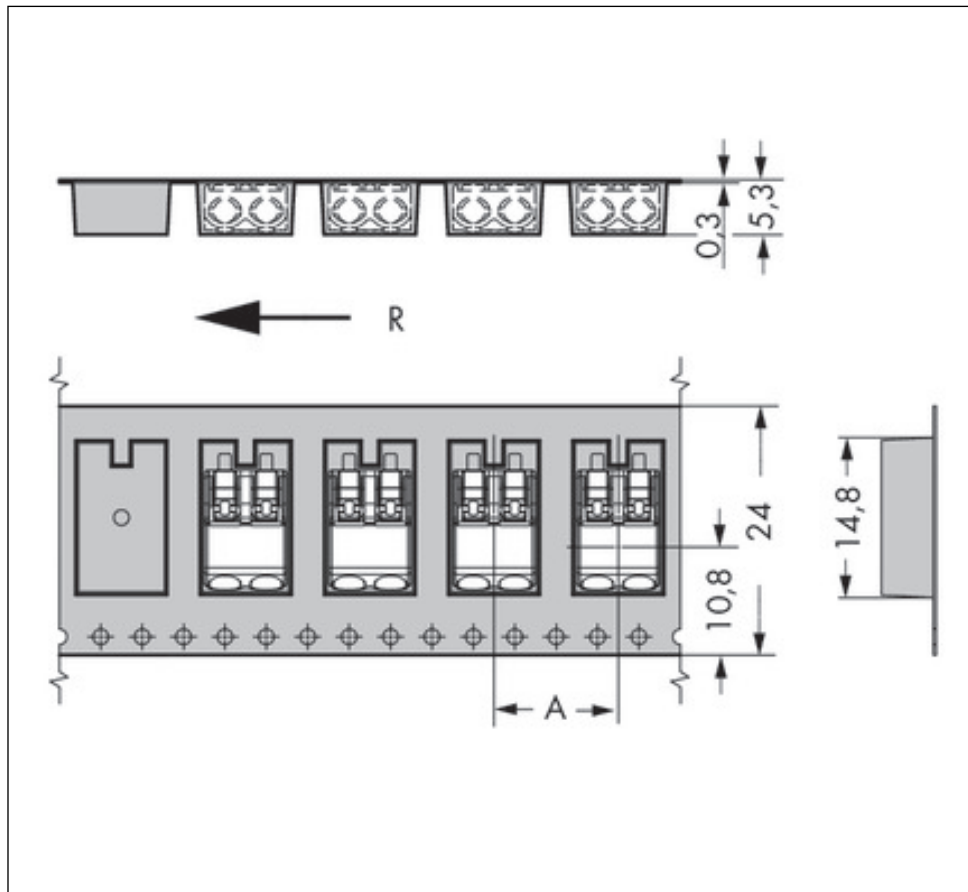

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.