

**Female connector; 4-pole; Pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable**

Item No.: 721-104/026-000



Female connector; 4-pole; Pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable

**Marking**

RoHS ✓  
Compliant

**Business data**

Supplier	WAGO
Item no.	721-104/026-000
GTIN / EAN	4044918353557
Content	1
Order amount	100
Customer item number	

**Notes**

Item description: Universal connection for all conductor types Easy cable pre-assembly and on-unit wiring via vertical and horizontal CAGE CLAMP® actuation Integrated test ports 100% protected against mismatching Coding option available


**Technical data**


*Miscellaneous*

No. of poles	4
Pin spacing	5 mm (0.197 in)
Total number of connection points	4
Total number of potentials	4
Color	light gray
Ratings according to 1	IEC/EN 60664-1
Rated voltage (III / 3) [V]	320 [V]

<b>Technical data</b>	
Rated surge voltage (III / 3) [kV]	4 [kV]
Rated voltage (III / 2) [V]	320 [V]
Rated surge voltage (III / 2) [kV]	4 [kV]
Rated voltage (II / 2) [V]	630 [V]
Rated surge voltage (II / 2) [kV]	4 [kV]
Nominal current [A]	16 [A]
Number of individual connection objects at the product	1
Number of levels	1
Connection technology	CAGE CLAMP®
Number of connection points	1
Actuation type	Betätigungswerkzeug
Solid sizes	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Fine-stranded wires	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Fine-stranded wires with insulated ferrule	0.25 ... 1.5 mm <sup>2</sup> / ...
Fine-stranded wires with uninsulated ferrule	0.25 ... 2.5 mm <sup>2</sup> / ...
Strip length	8 ... 9 mm / 0.31 ... 0.35 in
Material group	I
Insulating material	Polyamide 66 (PA 66)
Flammability rating per UL 94	V0
Limit temperature range	-60 ... 85 C
Clamping spring material	Chrome-nickel spring steel (CrNi)
Contact material	Copper alloy
Contact plating	tin-plated
Fire load [MJ]	0.106 [MJ]
Weight [g]	7.47 [g]
Width	21.5 mm / 0.846 in
Height	14.3 mm / 0.563 in
Length	26.45 mm / 1.041 in

**Images & drawings**

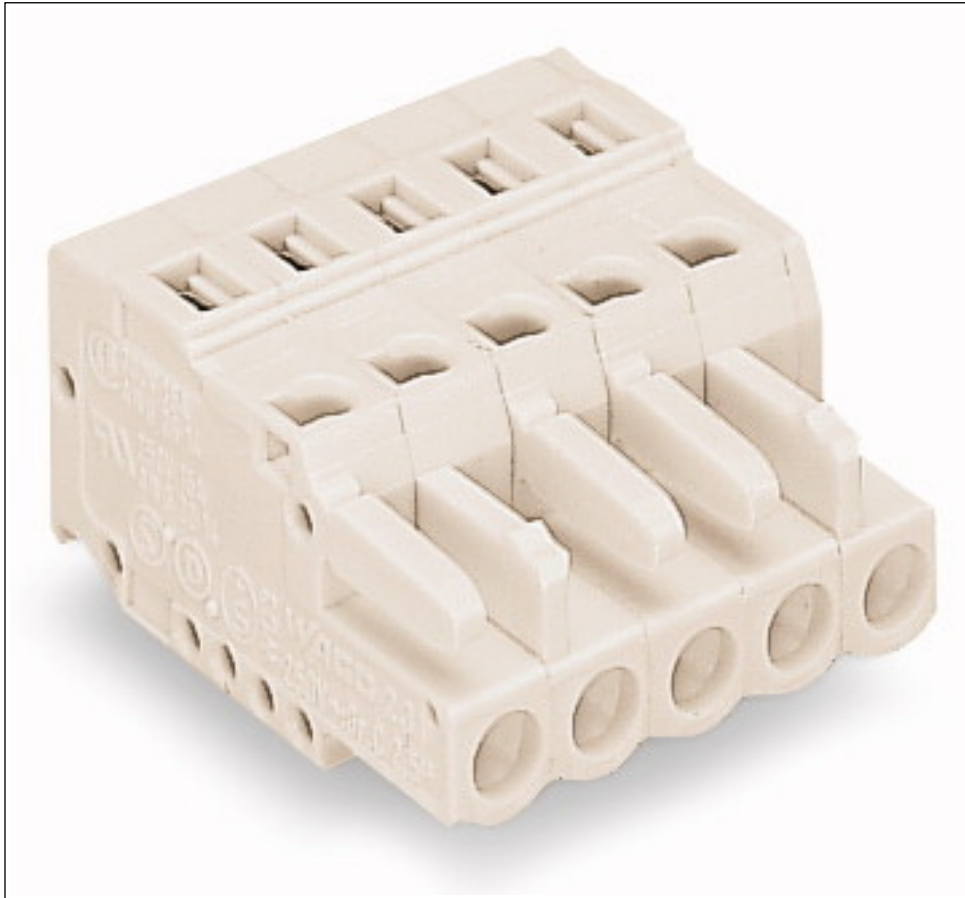

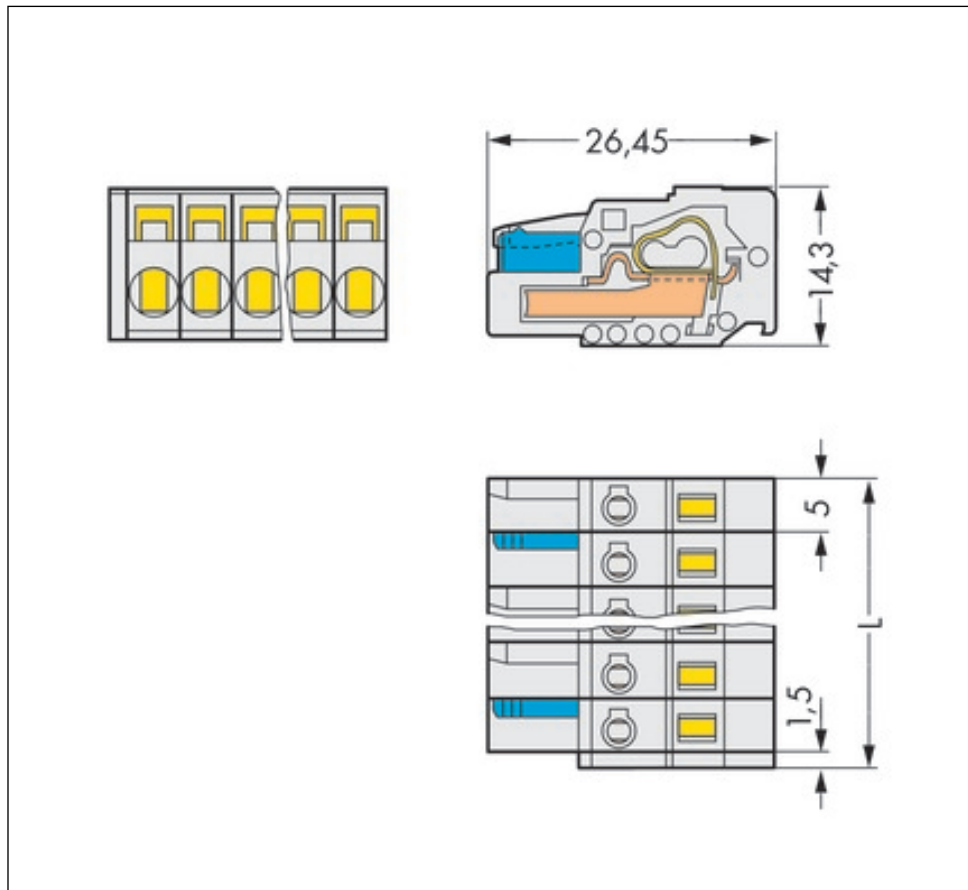

#### Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.