

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190730009](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Avikrimp™ Ring Tongue Terminal for 18 to 22 AWG Wire, Stud Size 6 (M3.5), Length 18.00mm

Documents:

3D Model	Product Specification PS-19902-013 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-011 (PDF)	

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19073
Comments	Type II Insulated; Class 1 and 2
Crimp Quality Equipment	Yes
Mil-Spec	AS25036-101, MS25036-101
Overview	Solderless Terminals
Product Name	Avikrimp™
Type	Ring
UPC	800753075016

Physical

Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	0.598/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	5-6 (M3-3.5)
Wire Insulation Diameter	3.60mm max.
Wire Size AWG	18, 20, 22
Wire Size mm²	0.35-0.80

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Old Part Number	AA-820-06
-----------------	-----------

Reference - Drawing Numbers

Product Specification	PS-19902-011, PS-19902-013
Sales Drawing	SD-19073-002

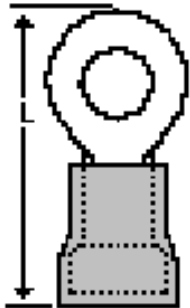

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/79/2015 (17
December 2015)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant

Search Parts in this Series

[19073](#) Series

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
PremiumGrade™	0640010100
Hand Crimp Tool	
Crimp Head for the	0640050100
AT-200™ Pneumatic	
Hand Tool	