

Stapelbare Ø 4 mm-Stecker


Stackable Ø 4 mm Plugs

Fiches Ø 4 mm à reprise arrière


SLS425-A/N




SLS425-A/N

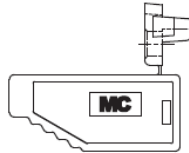

KT425-A

 

LS410N

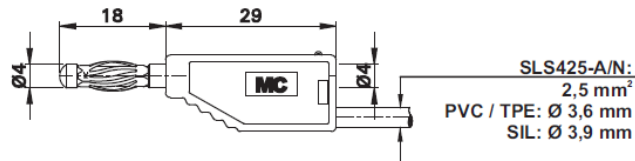

Stapelbare Ø 4 mm-Stecker mit federnder Kontaktlamelle für die Selbstmontage von Messleitungen. Vernickelte und vergoldete Versionen. Lötanschluss.

Stackable Ø 4 mm plugs with spring-loaded Multilam for self-assembly of test leads. Nickel-plated and gold-plated versions available. Solder connection.

Fiches à lamelles Ø 4 mm à reprise arrière, destinées à la confection de cordons de mesure. Disponibles en versions dorée et nickelée. Raccord à souder.

Typ Type Type	Best.-Nr. Order No. N° de Cde	Bemessungsspannung / -strom Rated voltage / current Tension / intensité assignée	Einzelteile: Knüpfülle / Stecker Component parts: Insulator / Plug Pièces détachées : Capuchon isolant / Fiche	*Farben *Colours *Couleurs
---------------------	-------------------------------------	--	--	----------------------------------

SLS425-A/N

22.2632*

30 V_{AC} ~ 60 V_{DC} / max. 32 A

KT425-A, 22.2160-* / LS410N, 22.5067

Ni

20	21	22	23	24
25	26	27	28	29

