


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0002092101](#)
Status: **Active**
Overview: Standard .093" Pin and Socket Connectors
Description: 2.36mm Diameter, Standard .093" Pin and Socket Crimp Terminal, Series 1190, Male, with Tin (Sn) Plated Brass Contact, 14-20 AWG, Reel

Documents:

Drawing (PDF)	Packaging Specification PK-1190-001 (PDF)
Product Specification PS-02-09 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-43660-9999 (PDF)	

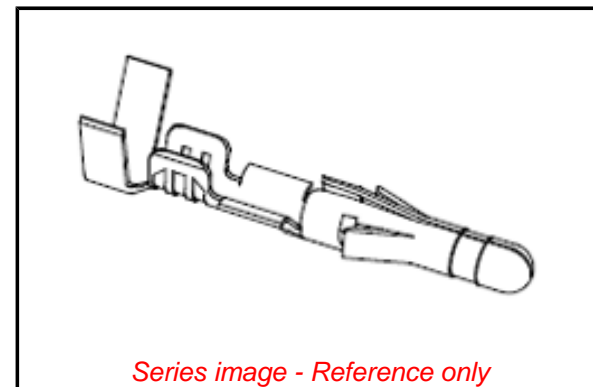

General

Product Family	Crimp Terminals
Series	1190
Application	Power
Crimp Quality Equipment	Yes
Overview	Standard .093" Pin and Socket Connectors
Packaging Alternative	02-09-2103 (Loose)
Product Name	Standard .093"
UPC	800753758612

Physical

Durability (mating cycles max)	25
Gender	Male
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.312/g
Packaging Type	Reel
Plating min - Mating	0.508µm
Plating min - Termination	0.508µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.65-4.06mm
Wire Size AWG	14, 16, 18, 20
Wire Size mm ²	N/A

Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Old Part Number	1190-(P901)
-----------------	-------------

Reference - Drawing Numbers

Packaging Specification	PK-1190-001
Product Specification	PS-02-09, PS-43660-9999
Sales Drawing	SD-1190-*

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/79/2015 (17
December 2015)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS
ELV

Green Image
Not Relevant

Search Parts in this Series

[1190 Series](#)

Use With

[1619](#) Plug or Receptacle Housing, [1545](#) Plug or Receptacle Housing, [1396](#) Plug or Receptacle Housing, [1490](#) Plug or Receptacle Housing, [2629](#) Plug or Receptacle Crimp Housings, [1261](#) Plug or Receptacle Housing, [1292](#) Plug or Recept

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Hand Crimper - DISTRIBUTION ONLY	<u>0638111000</u>
Insertion Tool	<u>0011020003</u>
Extraction Tool	<u>0011030006</u>
Terminator Die	<u>0011402001</u>
Extractor Tool for .093 and HCS-125 Product Series	<u>0638240200</u>
Mini-Mac™ Applicator	<u>0638927100</u>
Mini-Mac™ Applicator	<u>0638927300</u>

This document was generated on 06/10/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION