


Accessories

Rubber Feet *All rubber feet are self-adhesive except rubber eyelets*

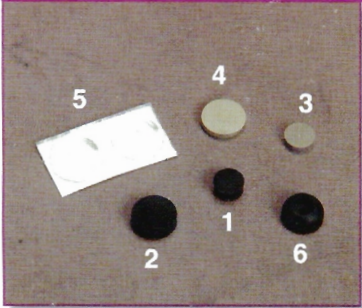

DIAMETER	THICKNESS	COLOR	MATERIAL	PART NUMBER
0.28"	0.12"	Black (1)	Rubber	ARF-01
0.39"	0.12"	Black (2)	Rubber	ARF-02
0.28"	0.06"	Gray (3)	Rubber	ARF-03
0.39"	0.06"	Gray (4)	Rubber	ARF-04
0.24"	0.08"	Transparent (5)	Clear Silicon	ARF-05
0.47"	0.14"	Transparent (5)	Clear Silicon	ARF-06
0.37"	0.17"	Black (6)	Rubber Eyelet	ARF-07

Every foot will not fit on every case. Call for a consultation.


Self-tapping screws



Self-tapping crosshead screws designed for plastics. Used for fastening components and PCB's to bosses.

DIAMETER	LENGTH	QUANTITY	PART NUMBER
0.10"	0.24"	1 pc	ASC-01
0.12"	0.24"	1 pc	ASC-02
0.12"	0.31"	1 pc	ASC-03


Battery Clips

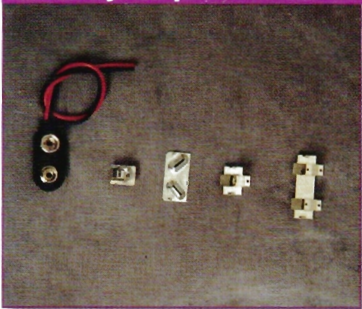

DESCRIPTION	SUPPLY	PART NUMBER
Clip Set For 4 x 1.5V AA Batteries	3 Double, 2 Single Clips (Large)	ABC-01
Clip Set For 2 x 9V Batteries	4 Single Clips (Large)	ABC-02
Clip Set For 2 x 1.5V AA Batteries	1 Double, 2 Single Clips (Large)	ABC-03
Clip Set For 1 x 9V Battery	2 Single Clips (Large)	ABC-04
Clip Set For 2 x 1.5 V AAA Batteries	1 Double, 2 Single Clips (Small)	ABC-05
Snap-on Connector for 1 x 9V Battery	1Pc	ABC-06

35

Belt Clips

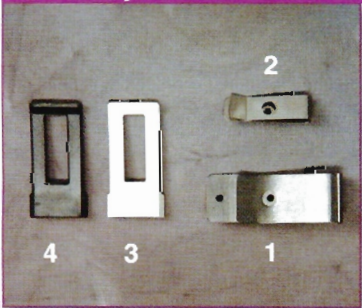

DESCRIPTION	PART NUMBER
Large Metal Stainless Steel Belt Clip (1)	ACL-01
Small Metal Stainless Steel Belt Clip (2)	ACL-02
Plastic Belt Clip In Off-White (3)	ACL-03
Plastic Belt Clip In Black (4)	ACL-04

Call for belt clip sizes.

Enclosure Protection

Custom rubber boot protection systems available - Call
 Custom sealing kits for various applications - Call
 Custom gaskets and O-rings for sealing screw holes - Call



Optional Orange Rubber Boot Shown

35