



4613 IBM PC, XT

Circuit Pattern:	3-Hole Solder Pad	<ul style="list-style-type: none"> • 3-hole solder pads (0.28" x 0.080") for interconnecting multiple component leads • I/O mounting area for 37-pin D-subminiature and ribbon cable connectors • Mounting bracket and hardware kit included (HD36B) • Layout paper and instructions included
Contacts:	31/62 @ .01" Ctrs, Ni/Gold	
Width/Thick:	13.25"/0.062"	
Height:	4.2"	
16-Pin DIP Capacity:	44	
Material:	FR4 Epoxy Glass	
V/G Terminals:	T44, T46, T49, T68	
Socket Pins:	R32	
Extender:	3690-22	
Hole Diameter:	.042"	

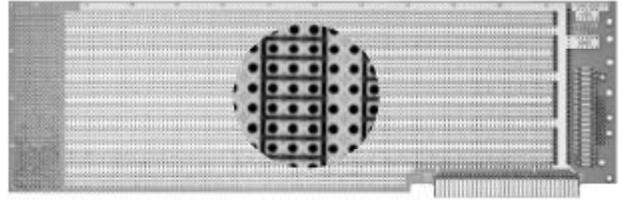


4613-1 IBM PC, XT

Circuit Pattern:	Peripheral Buses	<ul style="list-style-type: none"> • Voltage and ground buses around board perimeter, both sides • Auxiliary bus line along lower edge of board, both sides • I/O mounting area for 37-pin D-subminiature and ribbon cable connectors • Mounting bracket and hardware kit included (HD36B) • Layout paper and instructions included
Contacts:	31/62 @ .01" Ctrs, Ni/Gold	
Width/Thick:	13.25"/.062"	
Height:	4.2"	
16-Pin DIP Capacity:	93	
Material:	FR4 Epoxy Glass	
V/G Terminals:	T44, T46, T49, T68	
Socket Pins:	R32	
Extender:	3690-22	
Hole Diameter:	.042"	

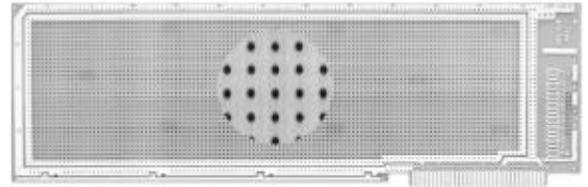

4613-2 IBM PC, XT

Circuit Pattern:	Voltage/Ground Planes	<ul style="list-style-type: none"> • Full voltage and ground planes on opposite sides • Three auxiliary bus lines along edge of board • 12 x 39 grid unrestricted component placement area with 0.080" diameter, isolated solder pads around holes • Layout paper and instructions included • Mounting bracket and hardware included (HD36B)
Contacts:	31/62 @ .01" Ctrs, Ni/Gold	
Width/Thick:	13.25"/.062"	
Height:	4.2"	
16-Pin DIP Capacity:	154	
Material:	FR4 Epoxy Glass	
V/G Terminals:	T44, T46, T49, T68	
Socket Pins:	R32	
Extender:	3690-22	
Hole Diameter:	.042"	

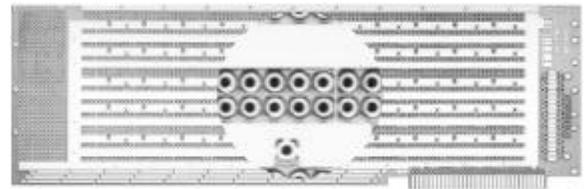

4613-3 IBM PC, XT

Circuit Pattern:	Pad-Per-Hole	<ul style="list-style-type: none"> • Plated-thru holes • Voltage and ground buses around board perimeter • I/O mounting area for 37-pin D-subminiature and ribbon cable connectors • Layout paper and instructions included • Mounting bracket and hardware included (HD36B)
Contacts:	31/62 @ .01" Ctrs, Ni/Gold	
Width/Thick:	13.25"/.062"	
Height:	4.2"	
16-Pin DIP Capacity:	154	
Material:	FR4 Epoxy Glass	
V/G Terminals:	T44, T46, T49, T68	
Socket Pins:	R32	
Extender:	3690-22	
Hole Diameter:	.042"	

