





# MALE ROD, DUAL ROTARY RING, TECHNOPOLYMER (R20/A)

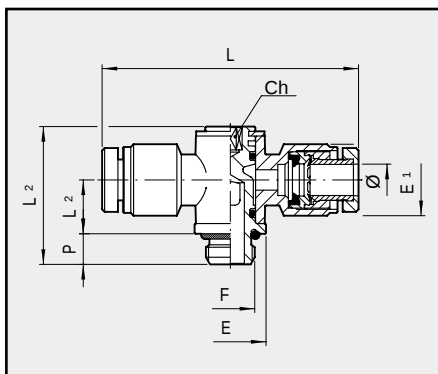


| Code     | Ref.  | Ø  | F   | Ch | P  | L  | L1   | L2   | E   | E1   |
|----------|-------|----|-----|----|----|----|------|------|-----|------|
| SERIES R |       |    |     |    |    |    |      |      |     |      |
| 2020A01  | R20/A | 4  | M5  | 2  | 4  | 40 | 16.8 | 6.5  | 9.9 | 10.9 |
| 2020A02  | R20/A | 4  | 1/8 | 3  | 6  | 45 | 27   | 10.5 | 14  | 12.5 |
| 2020A03  | R20/A | 5  | M5  | 2  | 4  | 43 | 18.8 | 8.5  | 9.9 | 13.5 |
| 2020A04  | R20/A | 5  | 1/8 | 3  | 6  | 46 | 27   | 10.5 | 14  | 13.5 |
| 2020A05  | R20/A | 6  | 1/8 | 3  | 6  | 45 | 27   | 10.5 | 14  | 15   |
| 2020A07  | R20/A | 6  | 1/4 | 4  | 8  | 48 | 31.5 | 11.5 | 18  | 15   |
| 2020A06  | R20/A | 8  | 1/8 | 3  | 6  | 51 | 27   | 10.5 | 14  | 16.3 |
| 2020A08  | R20/A | 8  | 1/4 | 4  | 8  | 54 | 31.5 | 11.5 | 18  | 16.3 |
| 2020A09  | R20/A | 10 | 1/4 | 4  | 8  | 64 | 31.5 | 11.5 | 18  | 18.5 |
| 2020A10  | R20/A | 12 | 1/4 | 4  | 9  | 64 | 31.5 | 11.5 | 18  | 21   |
| 2020A11  | R20/A | 12 | 3/8 | 5  | 11 | 68 | 36   | 13.5 | 22  | 21   |
| 2020A12  | R20/A | 12 | 1/2 | 8  |    | 72 | 42   | 16.2 | 26  | 21   |

# ELBOW, INTERMEDIATE, TECHNOPOLYMER (R21)

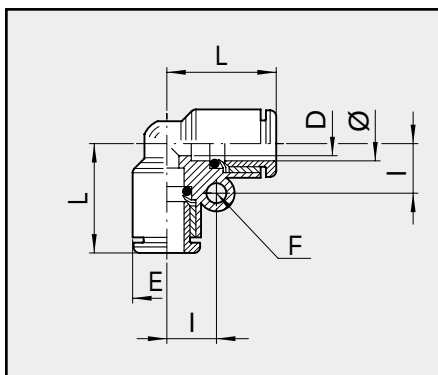


| Code                 | Ref. | Ø  | L    | D   | E    | I   | F   |
|----------------------|------|----|------|-----|------|-----|-----|
| MINIATURE SERIES FOX |      |    |      |     |      |     |     |
| 2L21001              | RL21 | 4  | 15.8 | 2.5 | 9.2  | 7.2 | 3.3 |
| 2L21003              | RL21 | 6  | 18.1 | 4.2 | 11.3 | 8.2 | 3.3 |
| 2L21004              | RL21 | 8  | 20.5 | 6.2 | 13.8 | 9.6 | 3.3 |
| SERIES R             |      |    |      |     |      |     |     |
| 2021001              | R21  | 4  | 19   | 3   | 12.5 | -   | -   |
| 2021002              | R21  | 5  | 20   | 3.5 | 13.5 | -   | -   |
| 2021003              | R21  | 6  | 20   | 4   | 15   | -   | -   |
| 2021004              | R21  | 8  | 23.5 | 6   | 16.5 | -   | -   |
| 2021005              | R21  | 10 | 27.5 | 8   | 18.5 | -   | -   |
| 2021006              | R21  | 12 | 32.5 | 10  | 21   | -   | -   |

# INTERMEDIATE TEE, TECHNOPOLYMER (R22)

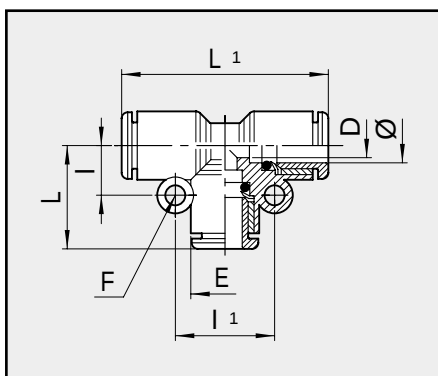

| Code                 | Ref. | Ø  | L    | L1   | D   | E    | I   | I1   | F   |
|----------------------|------|----|------|------|-----|------|-----|------|-----|
| MINIATURE SERIES FOX |      |    |      |      |     |      |     |      |     |
| 2L22001              | RL22 | 4  | 15.8 | 31.6 | 2.5 | 9.2  | 7.2 | 14.4 | 3.3 |
| 2L22003              | RL22 | 6  | 18.1 | 36.2 | 4.2 | 11.3 | 8.2 | 16.4 | 3.3 |
| 2L22004              | RL22 | 8  | 20.5 | 41   | 6.2 | 13.8 | 9.6 | 19.2 | 3.3 |
| SERIES R             |      |    |      |      |     |      |     |      |     |
| 2022001              | R22  | 4  | 19   | 38   | 3   | 12.5 | -   | -    | -   |
| 2022002              | R22  | 5  | 20   | 40   | 3.5 | 13.5 | -   | -    | -   |
| 2022003              | R22  | 6  | 20   | 40   | 4   | 15   | -   | -    | -   |
| 2022004              | R22  | 8  | 23.5 | 47   | 6   | 16.5 | -   | -    | -   |
| 2022005              | R22  | 10 | 27.5 | 55   | 8   | 18.5 | -   | -    | -   |
| 2022006              | R22  | 12 | 32.5 | 65   | 10  | 21   | -   | -    | -   |

# WYE (R23)

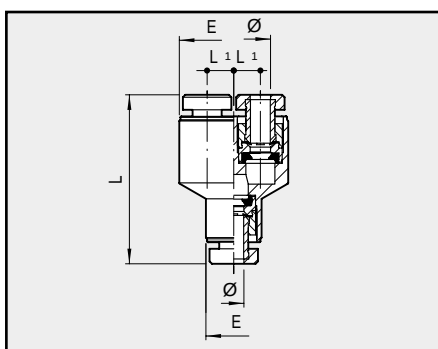

| Code     | Ref. | Ø | L    | L1  | E    |
|----------|------|---|------|-----|------|
| SERIES R |      |   |      |     |      |
| 2023001  | R23  | 4 | 34   | 5.5 | 11   |
| 2023002  | R23  | 5 | 35.5 | 6.5 | 13.5 |
| 2023003  | R23  | 6 | 35.5 | 7   | 14   |
| 2023004  | R23  | 8 | 44   | 8   | 16   |