

Printview: 2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 4-pole - Item No.: 262-154

WAGO® online catalog / eShop

2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 4-pole

Item No.: 262-154



2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 4-pole

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	262-154
GTIN / EAN	4044918642330
Content	1
Order amount	100
Customer item number	

Notes

Technical data

Miscellaneous



No. of poles	4
Total number of connection points	8
Total number of potentials	4
Color	gray
Pollution degree (1)	3
Rated voltage EN (1) [V]	630 [V]
Rated surge voltage (1) [kV]	8 [kV]

Printview: 2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 4-pole - Item No.: 262-154

Technical data	
Nominal current [A]	24 [A]
Connection technology (1)	CAGE CLAMP®
Solid sizes 1	0.08 ... 4 mm ² / 28 ... 12 AWG
Fine-stranded wires 1	0.08 ... 4 mm ² / 28 ... 12 AWG
Strip length 1	9 ... 10 mm / 0.35 ... 0.39 in
Type of wiring	Side-entry wiring
Design	horizontal
Marking level	Side marking
Fire load [MJ]	0.344 [MJ]
Weight [g]	18.54 [g]
Width	32.4 mm / 1.276 in
Height from the surface	23 mm / 0.906 in
Length	33.5 mm / 1.319 in
Module width [mm]	7 [mm]
Module width [inch] [inch]	0.276 [inch]

Printview: 2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 4-pole - Item No.: 262-154

Images & drawings

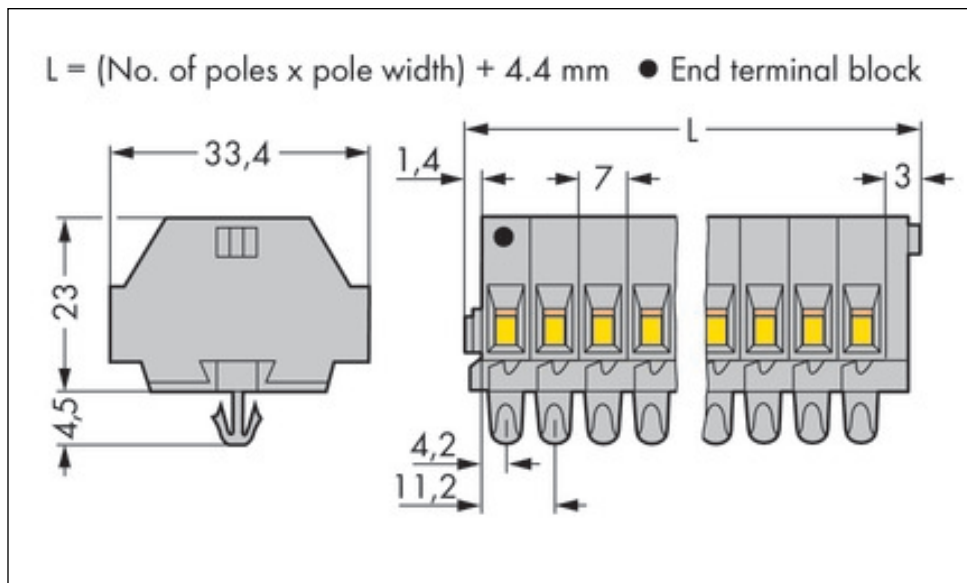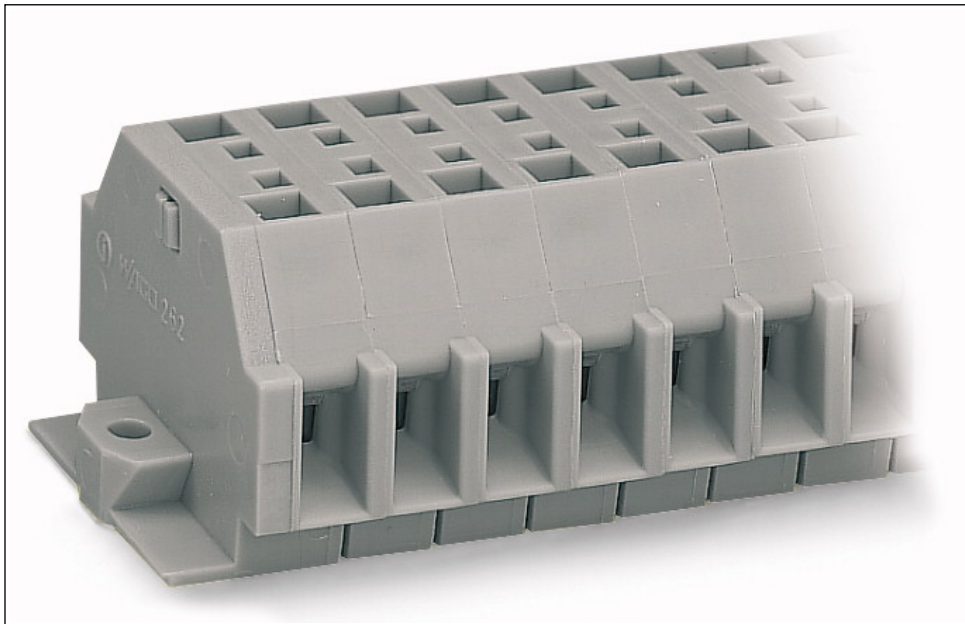

Printview: 2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 4-pole -
Item No.: 262-154

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.