

4-conductor ground terminal block

Item No.: 281-657



4-conductor ground terminal block

Marking

 RoHS ✓
 Compliant

Business data

Supplier	WAGO
Item no.	281-657
GTIN / EAN	4044918512008
Content	1
Order amount	50
Customer item number	

Notes


Technical data


Miscellaneous

Total number of connection points	4
Total number of potentials	1
Color	green-yellow
Ratings according to 1	IEC/EN 60947-7-2
Connection technology (1)	CAGE CLAMP®
Solid sizes 1	0.08 ... 4 mm ² / 28 ... 12 AWG
Fine-stranded wires 1	0.08 ... 4 mm ² / 28 ... 12 AWG
Strip length 1	9 ... 10 mm / 0.35 ... 0.39 in
Type of wiring	Front-entry wiring
Design	horizontal

Technical data	
<i>Marking level</i>	<i>Center marking</i>
<i>Insulating material</i>	<i>Polyamide 66 (PA 66)</i>
<i>Fire load [MJ]</i>	<i>0.193 [MJ]</i>
<i>Weight [g]</i>	<i>17.65 [g]</i>
<i>Width</i>	<i>6 mm / 0.236 in</i>
<i>Height from upper-edge of DIN-rail [mm]</i>	<i>29 [mm]</i>
<i>Height from upper-edge of DIN-rail</i>	<i>29 mm / 1.142 in</i>
<i>Length</i>	<i>86 mm / 3.386 in</i>
<i>Type of mounting</i>	<i>DIN 35 rail</i>

Images & drawings

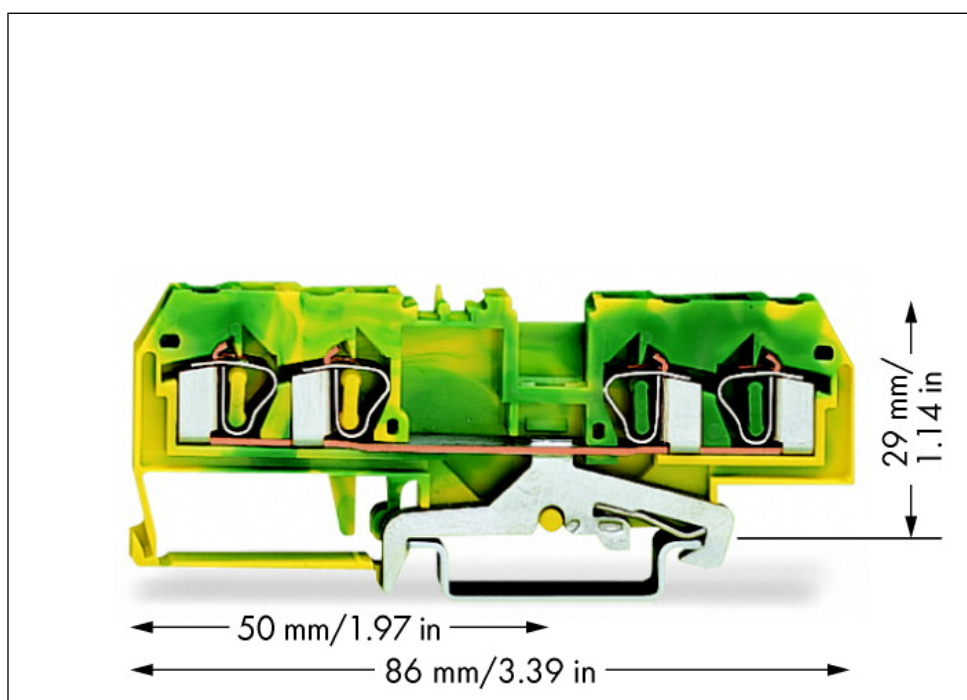

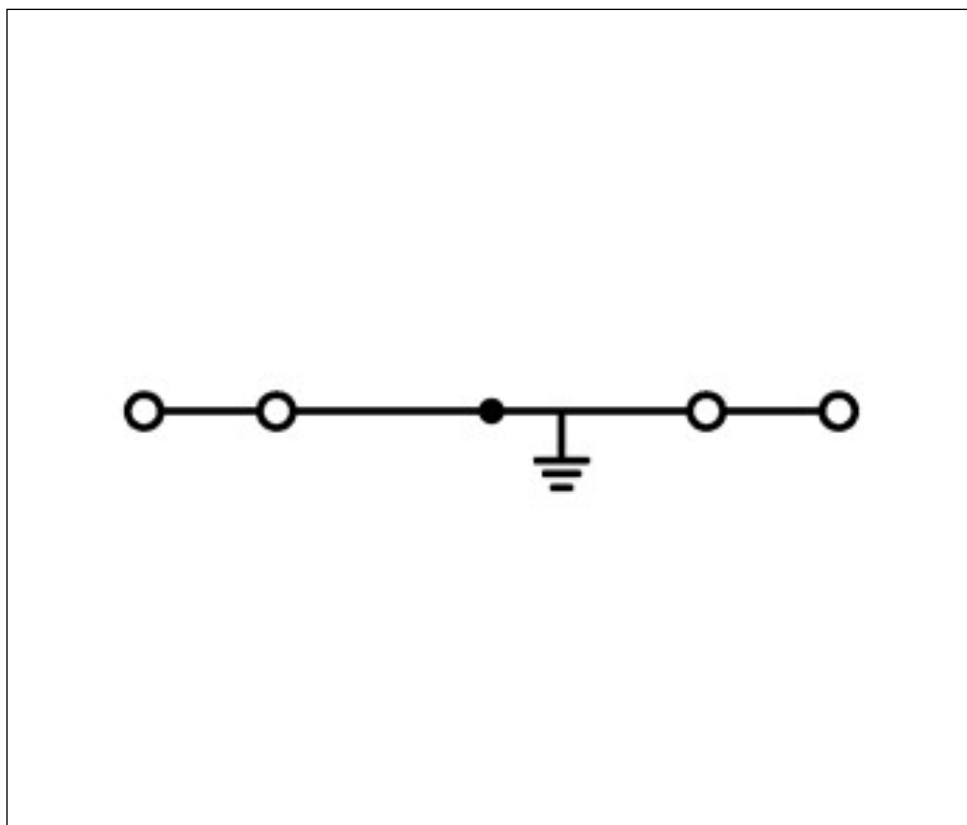

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.