


Printview: 2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 6-pole - Item No.: 260-156

WAGO® online catalog / eShop

2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 6-pole

Item No.: 260-156

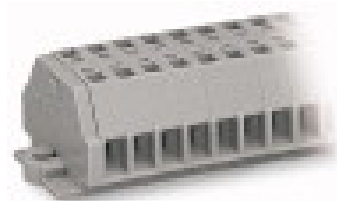

2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 6-pole

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	260-156
GTIN / EAN	4044918606936
Content	1
Order amount	50
Customer item number	

Notes

Technical data

Miscellaneous



No. of poles	6
Total number of connection points	12
Total number of potentials	6
Color	gray
Pollution degree (1)	3
Rated voltage EN (1) [V]	400 [V]
Rated surge voltage (1) [kV]	6 [kV]

Printview: 2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 6-pole - Item No.: 260-156

Technical data	
Nominal current [A]	18 [A]
Connection technology (1)	CAGE CLAMP®
Solid sizes 1	0.08 ... 1.5 mm ² / 28 ... 16 AWG
Fine-stranded wires 1	0.08 ... 1.5 mm ² / 28 ... 16 AWG
Strip length 1	8 ... 9 mm / 0.31 ... 0.35 in
Type of wiring	Side-entry wiring
Design	horizontal
Marking level	Side marking
Fire load [MJ]	0.207 [MJ]
Weight [g]	10.64 [g]
Width	34.4 mm / 1.354 in
Height from the surface	17 mm / 0.669 in
Length	25 mm / 0.984 in
Module width [mm]	5 [mm]
Module width [inch] [inch]	0.197 [inch]

Printview: 2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 6-pole - Item No.: 260-156

Images & drawings

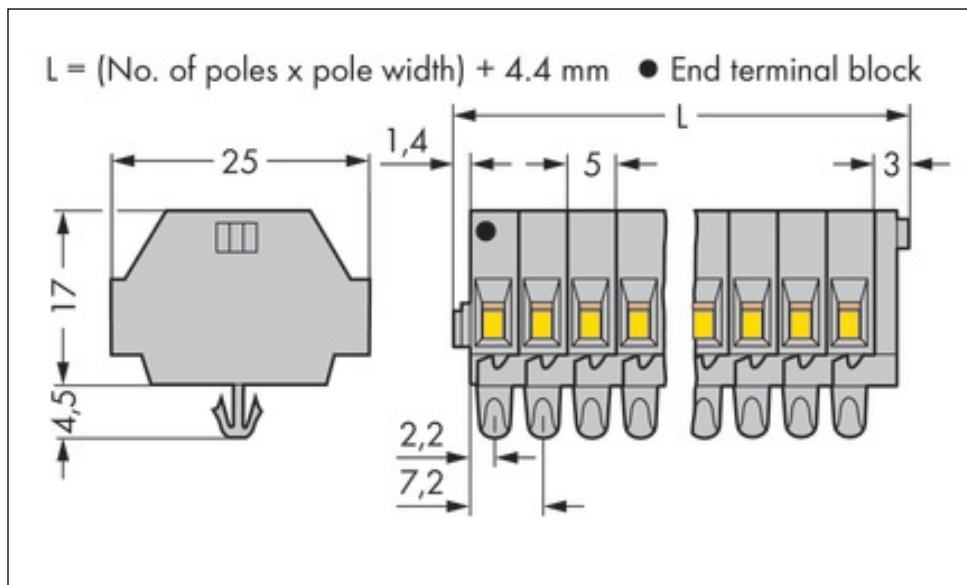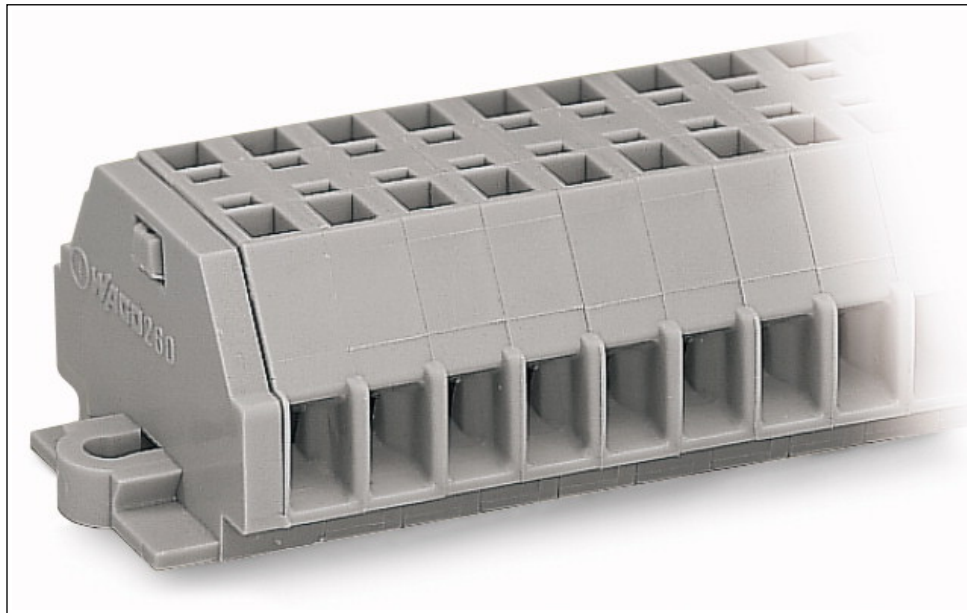

Printview: 2-conductor terminal strip; with snap-in mounting feet; for plate thickness 0.6 ... 1.2 mm; fixing hole 3.5 mm Ø; also fits 210-154 aluminum rail or with 209-123 mounting carrier for DIN 35 rail; 6-pole - Item No.: 260-156

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.