

Printview: 2-conductor terminal strip; with push-buttons on both sides; with fixing flanges; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail; 4-pole - Item No.: 261-104/341-000

WAGO® online catalog / eShop

2-conductor terminal strip; with push-buttons on both sides; with fixing flanges; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail; 4-pole

Item No.: 261-104/341-000



2-conductor terminal strip; with push-buttons on both sides; with fixing flanges; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail; 4-pole

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	261-104/341-000
GTIN / EAN	4044918618557
Content	1
Order amount	50
Customer item number	

Notes

Technical data

Miscellaneous



No. of poles	4
Total number of connection points	8
Total number of potentials	4
Color	gray
Pollution degree (1)	3
Rated voltage EN (1) [V]	500 [V]
Rated surge voltage (1) [kV]	6 [kV]
Nominal current [A]	24 [A]

Printview: 2-conductor terminal strip; with push-buttons on both sides; with fixing flanges; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail; 4-pole - Item No.: 261-104/341-000

Technical data	
Connection technology (1)	CAGE CLAMP®
Solid sizes 1	0.08 ... 2.5 mm ² / 28 ... 14 AWG
Fine-stranded wires 1	0.08 ... 2.5 mm ² / 28 ... 14 AWG
Strip length 1	8 ... 9 mm / 0.31 ... 0.35 in
Type of wiring	Side-entry wiring
Design	horizontal
Marking level	Side marking
Fire load [MJ]	0.237 [MJ]
Weight [g]	11.522 [g]
Width	38.5 mm / 1.516 in
Height from the surface	23.2 mm / 0.913 in
Length	28 mm / 1.102 in
Module width [mm]	6 [mm]
Module width [inch] [inch]	0.236 [inch]

Printview: 2-conductor terminal strip; with push-buttons on both sides; with fixing flanges; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail; 4-pole - Item No.: 261-104/341-000

Images & drawings

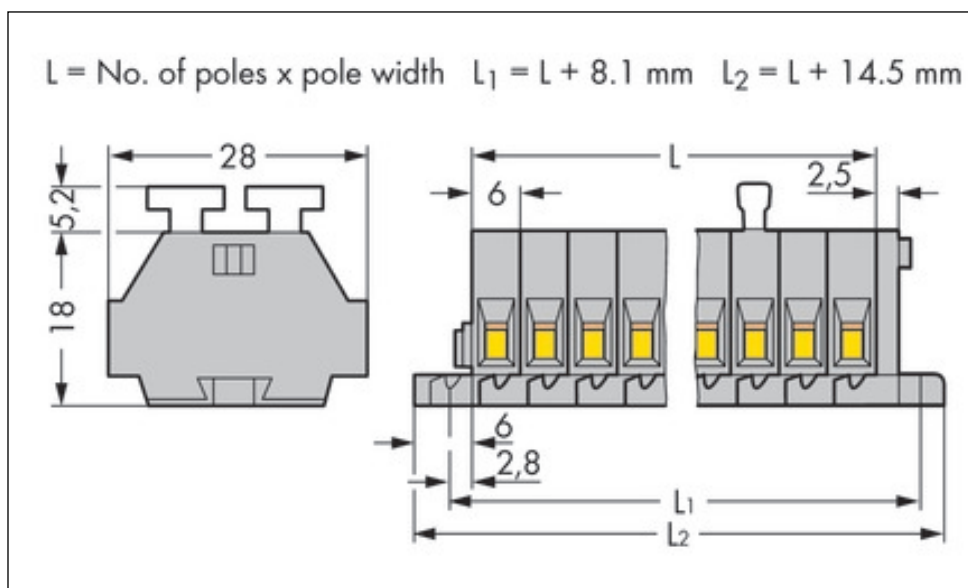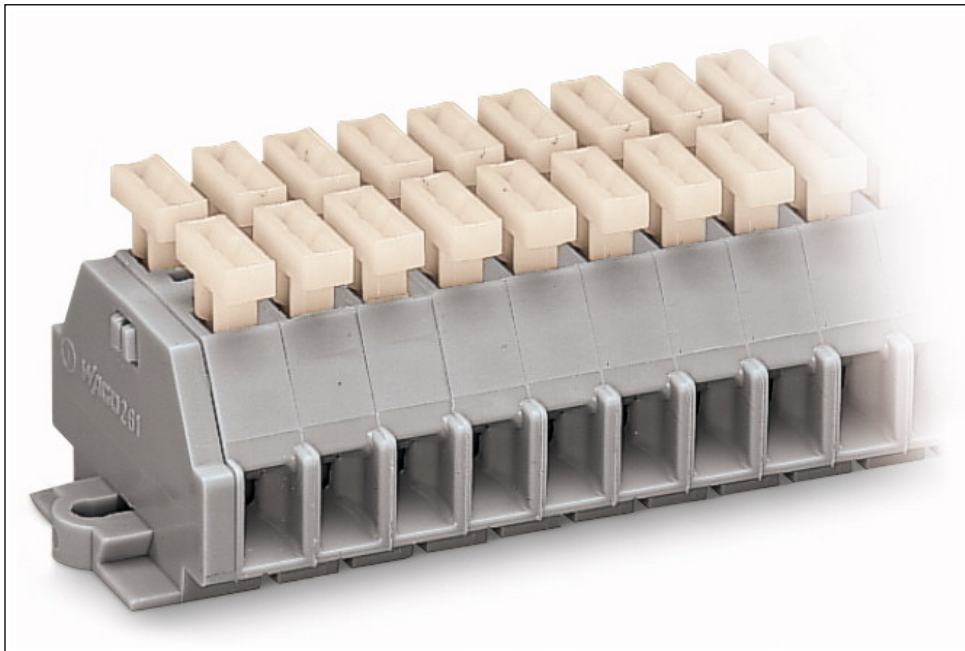

Printview: 2-conductor terminal strip; with push-buttons on both sides; with fixing flanges; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail; 4-pole - Item No.: 261-104/341-000

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.