

4-conductor chassis-mount terminal strip; for mounting via M3 screw and nut or self-tapping screw 2.9 mm Ø from top; plain; with 2x pin; 2-pole

Item No.: 862-552



4-conductor chassis-mount terminal strip; for mounting via M3 screw and nut or self-tapping screw 2.9 mm Ø from top; plain; with 2x pin; 2-pole

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	862-552
GTIN / EAN	4044918509145
Content	1
Order amount	500
Customer item number	

Notes

Technical data

Miscellaneous


No. of poles	2
Total number of connection points	8
Total number of potentials	2
Color	black
Pollution degree (1)	3
Rated voltage EN (1) [V]	500 [V]
Rated surge voltage (1) [kV]	6 [kV]
Nominal current [A]	32 [A]

Technical data	
Connection technology (1)	Push-in CAGE CLAMP®
Solid sizes 1	0.5 ... 4 mm² / 20 ... 12 AWG
solid, directly pluggable 1	0.5 ... 4 mm² / 20 ... 12 AWG
stranded, connectable 1	0.5 ... 4 mm² / 20 ... 12 AWG
Fine-stranded wires 1	0.5 ... 4 mm² / 20 ... 12 AWG
Fine-stranded wires with insulated ferrule 1	0.5 ... 4 mm² / 20 ... 12 AWG
min. fine-stranded with insulated ferrule, push-in terminati	0.5 mm² / 20 AWG
Strip length 1	10 ... 11 mm / 0.39 ... 0.43 in
Type of wiring	Side-entry wiring
Fire load [MJ]	0.262 [MJ]
Weight [g]	13.785 [g]
Width	24 mm / 0.945 in
Height from the surface	22.3 mm / 0.878 in
Length	35 mm / 1.378 in
Marking	plain

Printview: 4-conductor chassis-mount terminal strip; for mounting via M3 screw and nut or self-tapping screw 2.9 mm Ø from top; plain; with 2x pin; 2-pole - Item No.: 862-552

Images & drawings



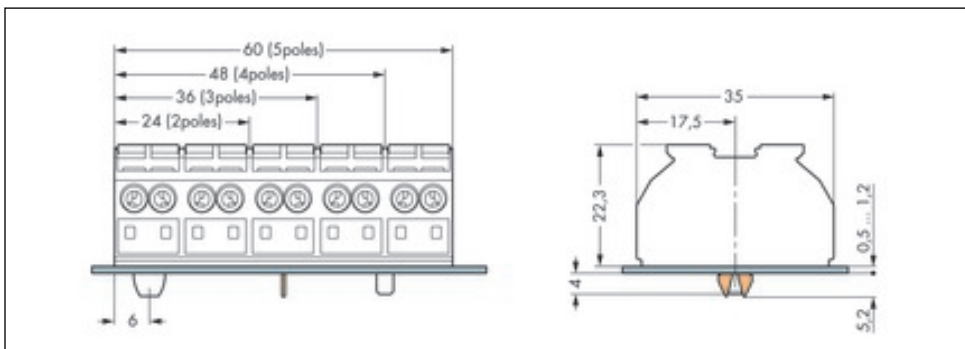

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.