

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0050579402
Status: Active
Overview: SL™ Modular Connectors
Description: SL™ Crimp Housing, Single Row, Version G, Positive Latch, 2 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Packaging Specification PK-70066-100 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series 70066
Application Signal, Wire-to-Board
Comments Version G
Overview SL™ Modular Connectors
Product Name SL™
UPC 800753577749

Physical

Circuits (maximum) 2
Color - Resin Black
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Keying to Mating Part Yes
Lock to Mating Part Yes
Material - Resin Polyester Alloy
Net Weight 0.200/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.54mm
Stackable No
Temperature Range - Operating -40°C to +105°C

Electrical

Current - Maximum per Contact 3.0A

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Old Part Number 70066-0176

Reference - Drawing Numbers

Packaging Specification PK-70066-100
Sales Drawing SD-70066-0176-0199

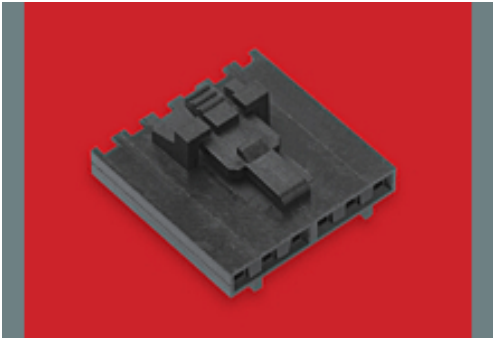

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Not Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

70066 Series

Mates With

70018 , 70543 , 70545 , 70553 , 70555 ,
70107 , 70541 , 70551 , 70634 , 74099

Use With

SL™ Crimp Terminal 70058 , 71851