


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191930305
Status: Active
Overview: VersaKrimp™ Terminals and Splices
Description: VersaKrimp™ Ring Tongue Terminal, 2 AWG

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19193
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	VersaKrimp™ Terminals and Splices
Product Name	VersaKrimp™
Type	Ring
UPC	800753040915
Physical	
Barrel Type	Closed - Brazed
Insulation	None
Material - Plating Mating	Tin
Net Weight	13.744/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	1/4" (M6)
Termination Interface: Style	Crimp or Compression
Wire Size AWG	2
Material Info	
Old Part Number	G-375-14
Reference - Drawing Numbers	
Sales Drawing	SD-19193-038

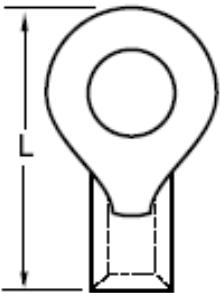

Series image - Reference only

EU ELV
Not Relevant

EU RoHS
Compliant
REACH SVHC
Not Contained Per -
ED/21/2016 (20 June
2016)
Halogen-Free
Status
Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant

Search Parts in this Series
[19193](#) Series

Application Tooling | FAQ
*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*
Global

Description	Product #
Hydraulic Dieless Crimping Tool	0638161700
Die Set (large) for the HHLS Hydraulic Crimper	0192900010
Manual tool for Crimping non- insulated 8AWG thru 4/0 Terminals	0192940008

Manual Putt Pump	<u>0192860117</u>
Hydraulic System,	
Die set required	
Square "DIN" style	<u>0640037970</u>
dies for 2 AWG	
Hand Crimp Tool	<u>0640013900</u>

This document was generated on 07/12/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION