

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0009501051
Status: Active
Overview: SPOX™ Wire-to-Board Connectors
Description: 3.96mm Pitch SPOX™ Crimp Housing, Female, with Friction Ramp, 5 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-5195-003 \(PDF\)](#)
[Product Specification PS-5273-003 \(PDF\)](#)
[Product Specification PS-5273-004 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series 5195
Application Signal, Wire-to-Board
Overview SPOX™ Wire-to-Board Connectors
Product Name SPOX™
UPC 800753534445

Physical


Circuits (maximum) 5
Color - Resin Natural
Flammability 94V-2
Gender Female
Glow-Wire Compliant No
Material - Resin Nylon
Net Weight 1467.100/mg
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 3.96mm
Pitch - Termination Interface 3.96mm
Stackable No
Temperature Range - Operating -40°C to +105°C

Material Info

Old Part Number 5195-05

Reference - Drawing Numbers

Product Specification PS-5195-003, PS-5273-003, PS-5273-004, RPS-5195-002
Sales Drawing SD-5195-N

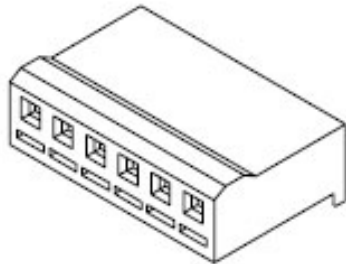

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS
ELV

Green Image
Not Relevant

Search Parts in this Series

5195 Series

Mates With

5272 , 5273 , 5274 right angle PCB header,
5096 , 53405 , 5271

Use With

5194 , 5225