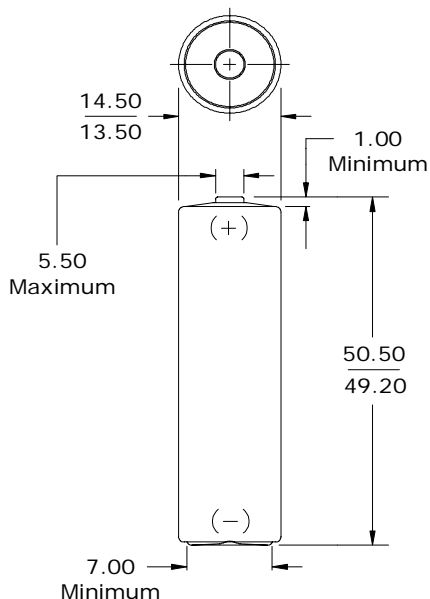


**EVEREADY SILVER NO. R6****AA***Zinc Chloride***Industry Standard Dimensions**

(millimeters)

**Specifications**

**Chemical System:** Zinc-Manganese Dioxide ( $\text{Zn/MnO}_2$ )  
(no added mercury or cadmium)

**Designation:** IEC-R6

**Nominal Voltage:** 1.5 volts

**Typical Capacity:** 1,100 mAh\* (to 0.8 volts)

(based on 25 mA continuous at 21°C)

\* Varies according to the applied load, temperature, and cutoff voltage.

**Operating Temp:** -18°C to 55°C

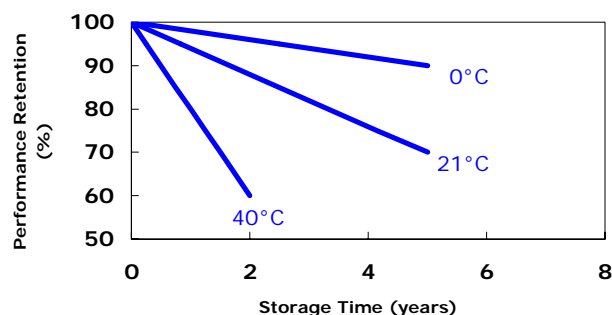
**Typical Weight:** 15 grams

**Typical Volume:** 8.0 cubic centimeters

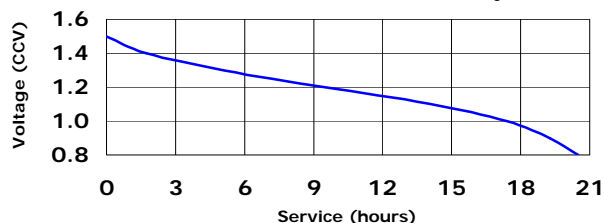
**Jacket:** Metal

**Storage/Capacity Characteristics**

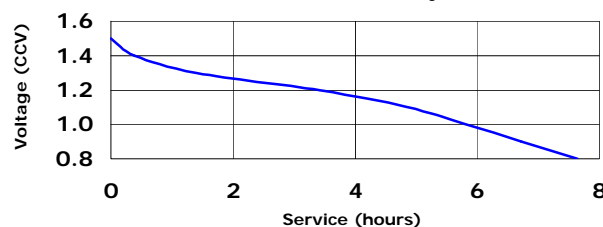
Effects of Storage at Various Temperatures

**Industry Standard Tests (21°C)****REMOTE**

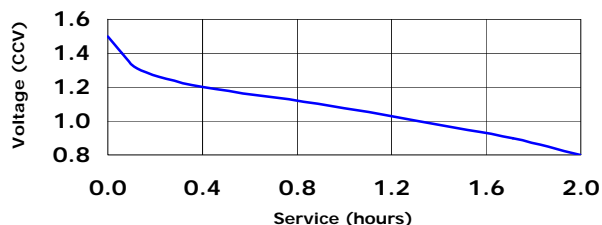
24 ohm 15 sec/min, 8 hrs/day

**TAPE PLAYER**

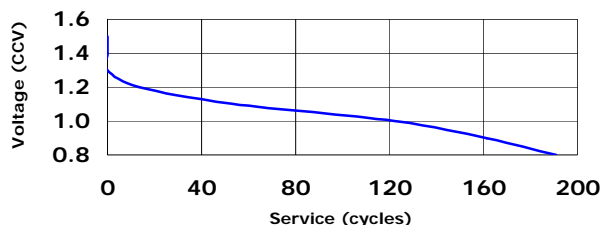
10 ohm 1 hr/day

**TOY**

3.9 ohm 1 hr/day

**PHOTOFLASH**

1.8 ohm 15 sec/min

**Important Notice**

This data sheet contains typical information specific to batteries manufactured at the time of its publication.

**Contents herein do not constitute a warranty.**

©Eveready Battery Company, Inc. - All Rights Reserved