

**Male Tab**  
**T&B Catalog Number:**

10RC-251T

**UPC Number:**


78621086974

**Status:**

Active

**Description:**

Nylon-Insulated Male Tab, Length 1.17 Inches, Width .45 Inches, Maximum Insulated .210, Tab Size .250x.032, Wire Range #12-#10 AWG, Color Yellow, Copper, Tin Plated

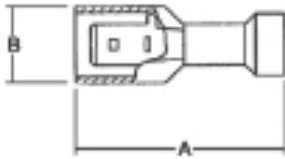

**WEB\_USE**

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

**General**

Style	Male - 250 Series
Insulation Type	Fully Insulated Nylon
Terminal Series	RC
Material	Brass
Finish	Electro -Tin Plated
Color	Yellow
Wire Range	12-10
Tab Size	.250 x .032

**Dimension Information**

Maximum Insulation (inches)	.250
Stock Thickness	.04
A (inches)	1.17
B (inches)	.45

**Specifications**

Temperature Rating	105°C
Voltage Rating	300V
Flammability Rating	UL 94 V-0

**Tooling**

Tool Charts	Available on Website
Application Tools	WT145C, WT2000, WT112M, ERG4001, ERG4003
Recommended Tool	ERG4001

**Packaging**

T&B Order Multiple	25
T&B Inner Pack	25
Package in Units	125
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	5 lbs. per 1000
Alternate Package Qty	RC25177

**Application Support**

Overview	Available on Website
Wire Guide Tables	Available on Website

**Certifications**

RoHS Compliance	Yes
-----------------	-----

## Certifications



File Nbr:  
E66716

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)