



Ring Terminal
T&B Catalog Number:

RA873

UPC Number:

78621081748

Status:

Active

Description:

Nylon Insulated Ring Terminal, Length .89 Inches, Width .31 Inches, Maximum Insulation .136, Bolt Hole #10, Wire Range #22-#16 AWG, Color Red, Copper, Tin Plated, 1,000 Pack


WEB_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Self-insulated with high dielectric-strength nylon sleeves. An inner bronze insulation grip sleeve lengthens the flexing radius of the conductor and eliminates conductor creep.

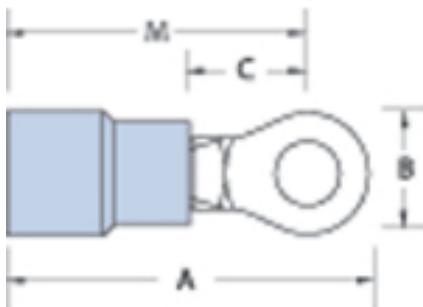

General

Insulation Type	Insulated Nylon
Terminal Series	RA
Material	Copper
Finish	Electro -Tin Plated
Color	Red
Wire Range	22-16
Stud Size	#10

Dimension Information

Maximum Insulation (inches)	.136
Stock Thickness	.03
A (inches)	.89
B (inches)	.31
C (inches)	.25
M (inches)	.74

Specifications

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-2
MIL Specification	MS-25036-103

Tooling

Tool Charts	Available on Website
Application Tools	WT2000, WT112M, WT145C, ERG4001, ERG4003, WT145A
Recommended Tool	WT145A

Packaging

T&B Order Multiple	1000
T&B Inner Pack	1000
Package in Units	10000
Package Type	Bulk
T&B Sold in UOM	Each
T&B Weight Per UOM	2.5 lbs. per 1000
Alternate Package Qty	RA18-14

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

Most terminals can be put on Mylar Tape for reel fed applications by adding the suffix M to the bulk catalog numbers.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com