



## Ferrule

### T&B Catalog Number:

F4003

### UPC Number:

78621033672

### Status:

Active

### Description:

Polypropylene-Insulated Old DIN Ferrule, Total Length .571 Inches/ 14.5mm, Pin Length .315 Inches/8mm, Pin Diameter .071 Inches/1.8mm, Base Diameter .134 Inches/3.4mm, Wire Range #16 AWG/1.50mm<sup>2</sup>, Color Red, Copper, Tin Plated


### WEB\_USE

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

### Features

Ferrules ensure reliable electrical connections when terminating conductors in screw clamp terminal blocks.

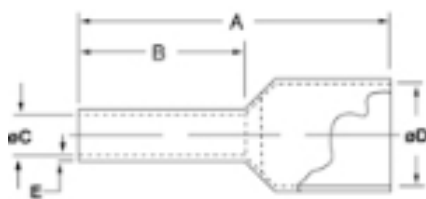

### General

|                              |                     |
|------------------------------|---------------------|
| Ferrule Type                 | OLD DIN             |
| Insulation Type              | Polypropylene       |
| Material                     | Copper              |
| Finish                       | Electro -Tin Plated |
| Color                        | Red                 |
| Wire Range                   | 16                  |
| Wire Size (mm <sup>2</sup> ) | 1.50                |

### Dimension Information

|                     |      |
|---------------------|------|
| A (mm)              | 14.5 |
| B (mm)              | 8.0  |
| Diameter C (inches) | .071 |
| Diameter C (mm)     | 1.8  |
| Diameter D (inches) | .134 |
| Diameter D (mm)     | 3.4  |
| E (mm)              | .15  |
| A (inches)          | .571 |
| B (inches)          | .315 |
| E (inches)          | .006 |

### Specifications

|                     |       |
|---------------------|-------|
| Temperature Rating  | 105°C |
| Flammability Rating | 94HB  |

### Tooling

|                   |                      |
|-------------------|----------------------|
| Tool Charts       | Available on Website |
| Application Tools | T1, T3, ERG4         |
| Recommended Tool  | T1, T3, ERG4         |

### Packaging

|                    |                    |
|--------------------|--------------------|
| T&B Order Multiple | 500                |
| T&B Inner Pack     | 500                |
| Package in Units   | 10000              |
| T&B Sold in UOM    | Each               |
| T&B Weight Per UOM | 0.63 lbs. per 1000 |

### Application Support

|                    |                      |
|--------------------|----------------------|
| T&B Sales Drawings | wsd-000402           |
| Overview           | Available on Website |
| Wire Guide Tables  | Available on Website |

#### Notes

Ferrule dimensions conform to DIN 46228, Part 4.

#### Certifications

|                 |     |
|-----------------|-----|
| RoHS Compliance | Yes |
|-----------------|-----|

#### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)