


Model 2BA & 2BC Double Banana Plug Both Ends Cable Assembly

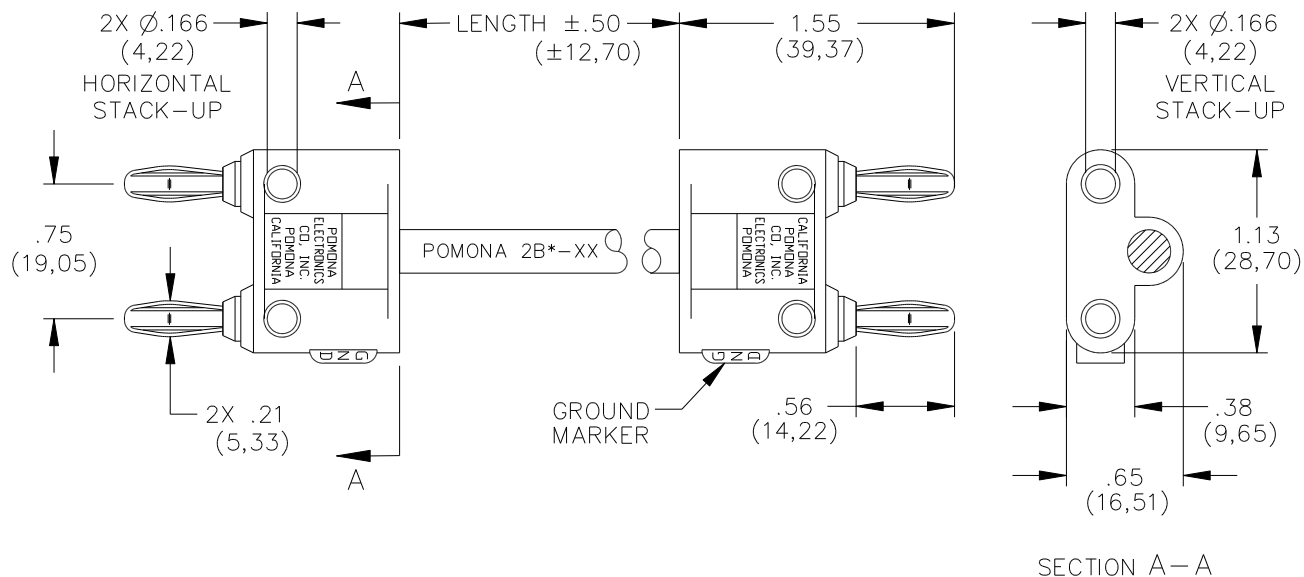

* = Cable

MATERIALS:

Banana Plugs:

Plug Bodies: Brass, Nickel Plated

Springs: Beryllium Copper, Nickel Plated

Insulation: Polypropylene Molded to the Plug Bodies and Cable. Color Matches Color of Cable

Marking: POMONA ELECTRONICS CO. INC. POMONA CALIFORNIA

Cable: 2BA: 2 Cond. Tw. 18 AWG 65 x 36 .250 (6,4) O.D., Color: Gray, Marking: 2BA-XX

2BC: RG58C/U, .195 (5,0) O.D., Color: Black, Marking: 2BC-XX

RATINGS:

Operating Temperature: +55°C Max.

Operating Voltage: 2BA – 300 VRMS, 2BC – 1400 VRMS

ORDERING INFORMATION: Model 2BA-XX

XX = Cable Length, Standard Lengths: 18" (457,2cm), 24" (60,96cm), 36" (91,44cm), 48" (121,92cm) & 60" (152,4cm).

Model 2BC-XX

XX = Cable Length, Standard Lengths: 24" (60,96cm), 36" (91,44cm), 48" (121,92cm) & 60" (152,4cm).

Ordering Example: 2BA-18 Cable Assembly is 18" (457,2cm), Cable is 2 Cond. Twisted Pair

Additional lengths can be quoted upon request.

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA