

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0002092101](#)  
**Status:** **Active**  
**Overview:** Standard .093" Pin and Socket Connectors  
**Description:** 2.36mm Diameter, Standard .093" Pin and Socket Crimp Terminal, Series 1190, Male, with Tin (Sn) Plated Brass Contact, 14-20 AWG, Reel

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification PK-1190-001 (PDF)</a>
<a href="#">Product Specification PS-02-09 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-43660-9999 (PDF)</a>	

**General**

Product Family	Crimp Terminals
Series	<a href="#">1190</a>
Application	Power
Crimp Quality Equipment	Yes
Overview	<a href="#">Standard .093" Pin and Socket Connectors</a>
Packaging Alternative	<a href="#">02-09-2103 (Loose)</a>
Product Name	Standard .093"
UPC	800753758612

**Physical**

Durability (mating cycles max)	25
Gender	Male
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.312/g
Packaging Type	Reel
Plating min - Mating	0.508µm
Plating min - Termination	0.508µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.65-4.06mm
Wire Size AWG	14, 16, 18, 20
Wire Size mm <sup>2</sup>	N/A

**Solder Process Data**


Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

Old Part Number	1190-(P901)
-----------------	-------------

**Reference - Drawing Numbers**

Packaging Specification	PK-1190-001
Product Specification	PS-02-09, PS-43660-9999
Sales Drawing	SD-1190-*

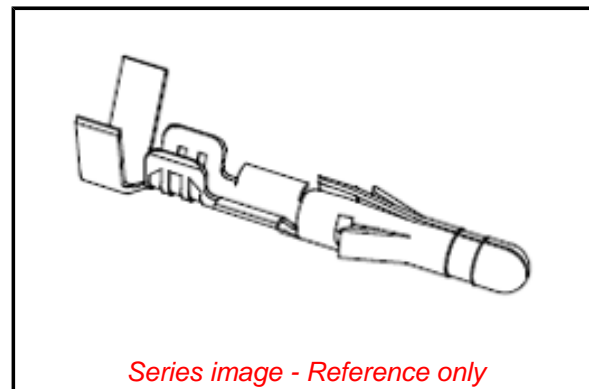

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**China RoHS**

**REACH SVHC**

Not Contained Per - ED/21/2016 (20 June 2016)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS  
ELV

Green Image  
Not Relevant

**Search Parts in this Series**

[1190 Series](#)

**Use With**

[1619](#) Plug or Receptacle Housing, [1545](#) Plug or Receptacle Housing, [1396](#) Plug or Receptacle Housing, [1490](#) Plug or Receptacle Housing, [2629](#) Plug or Receptacle Crimp Housings, [1261](#) Plug or Receptacle Housing, [1292](#) Plug or Recept

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

<b>Description</b>	<b>Product #</b>
Insertion Tool	<a href="#">0011020003</a>

Hand Crimper - DISTRIBUTION ONLY	<u>0638111000</u>
Extraction Tool	<u>0011030006</u>
Terminator Die	<u>0011402001</u>
Extractor Tool for .093 and HCS-125 Product Series	<u>0638240200</u>
Mini-Mac™ Applicator	<u>0638927100</u>
Mini-Mac™ Applicator	<u>0638927300</u>

This document was generated on 08/01/2016

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**