

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


5034730200

Status:

Active

Description:

Flexi-Mate™ 3.70mm Pitch Wire-to-Board Plug Housing, Right Angle, 3.00mm Stacking Height, 2 Circuits

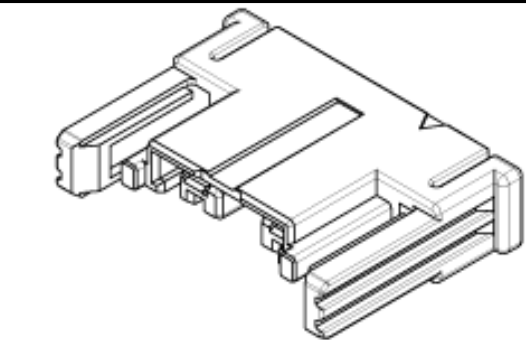

Series image - Reference only

Documents:	
3D Model	Application Specification AS-503471-001 (PDF)
Drawing (PDF)	Packaging Specification SPK-503473-001 (PDF)
Product Specification PS-503471-001 (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	503473
Application	Signal, Wire-to-Board
Product Name	Flexi-Mate™
UPC	883906918675
Physical	
Circuits (maximum)	2
Color - Resin	White
Flammability	94HB
Gender	Plug
Glow-Wire Compliant	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Net Weight	165.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.70mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +85°C
Electrical	
Current - Maximum per Contact	2.0A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-503471-001
Packaging Specification	SPK-503473-001
Product Specification	PS-503471-001, RPS-503471-002, RPS-503471-005, RPS-503471-007, RPS-503473-001
Sales Drawing	SD-503473-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/79/2015 (17
December 2015)

Halogen-Free

Status

Not Low-Halogen

Need more information on product
environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS
ELV

Green Image
Not Relevant

Search Parts in this Series

[503473](#) Series

Mates With

[503471](#) PCB Receptacle

Use With

[503485](#) Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION