

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0510060300**
Status: **Active**
Description: 2.00mm Pitch Wire-to-Wire Plug Housing, 3 Circuits

Documents:

3D Model [Packaging Specification SPK-51006-001 \(PDF\)](#)
Drawing (PDF) [RoHS Certificate of Compliance \(PDF\)](#)
Product Specification PS-51005-001 (PDF)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series 51006
Application Signal, Wire-to-Wire
MolexKits Yes
Product Name N/A
UPC 800753630246

Physical

Circuits (maximum) 3
Color - Resin Natural
Flammability 94V-0
Gender Male
Glow-Wire Compliant No
Lock to Mating Part None
Material - Resin Polyester
Net Weight 160.000/mg
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.00mm
Stackable No
Temperature Range - Operating -40°C to +105°C


Electrical

Current - Maximum per Contact 2.0A

Material Info

Reference - Drawing Numbers

Packaging Specification SPK-51006-001
Product Specification PS-51005-001
Sales Drawing SD-51006-001

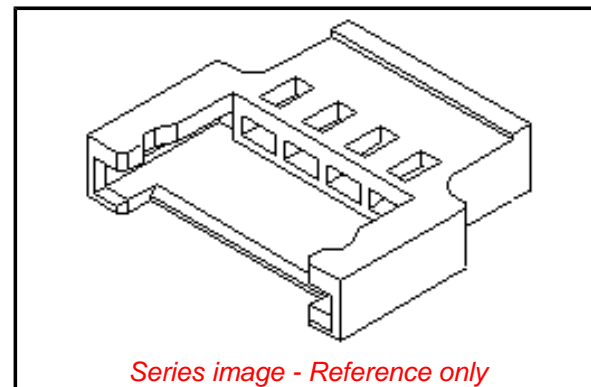

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per
-ED/79/2015 (17
December 2015)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

51006 Series

Mates With

51005 Female Housing

Use With

50012