

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION


Part Number: [0467651001](#)
Status: **Active**
Overview: [High Definition Multimedia Interface \(HDMI*\) Micro Connectors](#)
Description: 0.40mm Pitch Micro HDMI* Connector, Right Angle Receptacle, Surface Mount, with Through Hole Shell Tabs and Kapton Tape, 19 Circuits, Lead-Free

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-46765-003 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
CSA	LR19980
General	
Product Family	I/O Connectors
Series	46765
Application	Wire-to-Board
Component Type	Receptacle
Overview	High Definition Multimedia Interface (HDMI*) Micro Connectors
Product Name	Micro HDMI*
Type	D
UPC	884982008571

Physical	
Boot Color	N/A
Circuits (Loaded)	19
Circuits (maximum)	19
Flammability	94V-0
Gender	Male
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	High Temperature Thermoplastic
Net Weight	0.309/g
Number of Rows	2
Orientation	Right Angle
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Panel Mount	No
Pitch - Mating Interface	0.40mm
Pitch - Termination Interface	0.40mm
Plating min - Mating	0.762µm
Plating min - Termination	0.051µm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	1
Termination Interface: Style	Surface Mount
Waterproof / Dustproof	No

Electrical	
Current - Maximum per Contact	0.8A
Grounding to Panel	Yes
Shield Type	Full Shield
Shielded	Yes

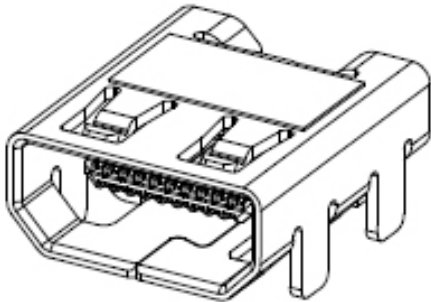

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per -ED/79/2015 (17 December 2015) Halogen-Free Status Low-Halogen	China RoHS
---	-------------------

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS ELV	Green Image Not Relevant
-------------------	-----------------------------

Search Parts in this Series
[46765](#) Series

Mates With
[68786](#) Micro HDMI* Cable Assemblies

Voltage - Maximum	30V
Solder Process Data	
Duration at Max. Process Temperature (seconds)	010
Lead-freeProcess Capability	REFLOW
Max. Cycles at Max. Process Temperature	002
Process Temperature max. C	260

Material Info

Reference - Drawing Numbers

Electrical Model Document	EE-46765-001
Product Specification	PS-46765-003, RPS-46765-003, RPS-46765-203
Sales Drawing	SD-46765-001

* High Definition Multimedia Interface and HDMI are trademarks of HDMI Licensing, LLC.

This document was generated on 03/29/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION