

Sample set - SAMPLE PTSM 0,5/ 6-HHI-2,5-THR - 1820893

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Header, Nominal current: 6 A, Rated voltage (III/2): 160 V, Number of positions: 6, Pitch: 2.5 mm, Color: black, Contact surface: Tin, Mounting: THR soldering


The illustration shows a 3-position version

Why buy this product

- Supplied in tape-on-reel packing according to IEC 60286-3 for automated mounting
- Specifically designed for use in reflow/soldering processes

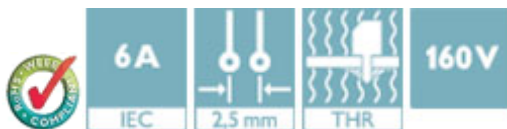

Key Commercial Data

Packing unit	5 pc
Minimum order quantity	5 pc
GTIN	 4 046356 787567
Weight per Piece (excluding packing)	1.86 g
Custom tariff number	85369010
Country of origin	Germany

Technical data

Product type	PCB headers
Rated voltage (IEC)	160
Rated current (IEC)	6
Mounting type	THR soldering
Number of positions	6
Pitch	2.5 mm
Levels	single-level
Type of locking	without
Plug-in system	COMBICON COMPACT PTSM
Product family	PTSM 0,5/..-HHI-THR

Sample set - SAMPLE PTSM 0,5/ 6-HHI-2,5-THR - 1820893

Technical data

Contact type	Female connector
--------------	------------------

Classifications

eCl@ss

eCl@ss 4.0	27141111
eCl@ss 4.1	27141109
eCl@ss 5.0	27141190
eCl@ss 5.1	27141190
eCl@ss 6.0	27261101
eCl@ss 7.0	27440401
eCl@ss 8.0	27440402
eCl@ss 9.0	27440402

ETIM


ETIM 3.0	EC001121
ETIM 4.0	EC002643
ETIM 5.0	EC002637

UNSPSC

UNSPSC 6.01	30211801
UNSPSC 7.0901	39121432
UNSPSC 11	34131203
UNSPSC 12.01	39121432
UNSPSC 13.2	39121432

Drawings

Drilling diagram

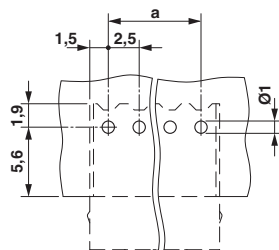

Dimensional drawing

