

M12-Round-Plug Connector, Single-Ended Cordsets, According to IEC 61076-2-101

RST




RST 8-627

3-, 4-, 5-, and 8-Poles

Actuator/sensor cordset, single-ended, M12, 3-, 4-, 5-, and 8-poles, male straight connector with self-locking thread and molded cable.


RST

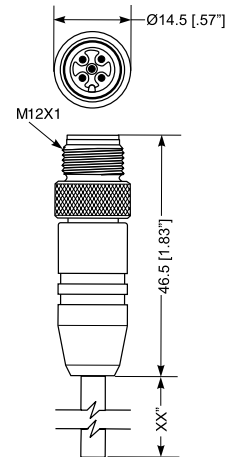


Pin Assignments

M12 - Male

 
3 poles




4 poles

 


5 poles (794)

 


5 poles (all others)

 

8 poles

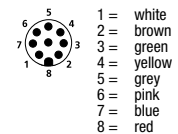

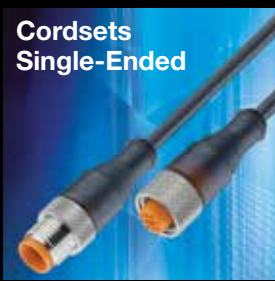

M12-Round-Plug Connector, Single-Ended Cordsets, According to IEC 61076-2-101

RST

Technical Data

Environmental

Degree of protection
Operating temperature range

IP 67 / NEMA 6P
PUR: -40°C (-40°F) / +80°C (176°F)
PVC: -40°C (-40°F) / +90°C (194°F)
TPE: -40°C (-40°F) / +90°C (194°F)

Mechanical

Housing / Molded body

PUR, yellow
RST 8-627: PUR, black

Insert

PUR, Yellow
RST 8-627/727: PUR, orange

Contacts

CuSn, gold over nickel-plated

Coupling nut

CuZn, nickel-plated

Electrical

Current rating
RST 8-XXX:

4 A
1.5A

Voltage rating

250 V
5-Pole: 60V
8-Pole: 30 V AC /36 V DC

Cable Specifications

Cable No.	Outer Jacket	Gauge	Jacket Color	OD
602	PUR	18AWG	Yellow	.230" (5.8 mm)
Continuous flex rating and suitable for general C-track usage. 1 million cycles at minimum bend radius 10X cable diameter.				
610	PUR	22AWG	Yellow	.190" (4.8 mm)
612	PVC	22AWG	Yellow	.210" (5.3 mm)
627	PVC	24AWG	Black	.232" (5.9 mm)
632	PVC	22AWG	Yellow	.190" (4.8 mm)
633	PVC	22AWG	Yellow	.190" (4.8 mm)
637	TPE/PLTC	18AWG	Yellow	.280" (7.1 mm)
643	TPE/PLTC	22AWG	Yellow	.246" (6.2 mm)
644	PUR	22AWG	Yellow	.210" (5.3 mm)
645	PUR	18AWG	Yellow	.220" (5.6 mm)
679	PUR	22AWG	Yellow	.190" (4.8 mm)
713	TPE/PLTC	22AWG	Yellow	.280" (7.1 mm)
727	TPE/PLTC	22AWG	Yellow	.335" (8.5 mm)
731	TPE/PLTC	18AWG	Yellow	.261" (6.6 mm)
794	TPE/PLTC	18AWG	Yellow	.304" (7.7 mm)

Part Number	Pins	Outer Jacket	Standard Cable Lengths	Characteristics
RST 3-731/...M	3	TPE/PLTC	2 M / 5 M / 10 M	
RST 3-632/...M		PVC	2 M / 5 M / 10 M	
RST 3-645/...M		PUR	2 M / 5 M / 10 M	
RST 3-610/...M		PUR	2 M / 5 M / 10 M	
RST 4-637/...M	4	TPE/PLTC	2 M / 5 M / 10 M	
RST 4-633/...M		PVC	2 M / 5 M / 10 M	
RST 4-643/...M		TPE/PLTC	2 M / 5 M / 10 M	
RST 4-602/...M		PUR	2 M / 5 M / 10 M	
RST 4-679/...M		PUR	2 M / 5 M / 10 M	
RST 5-612/...M	5	PVC	2 M / 5 M / 10 M	
RST 5-644/...M		PUR	2 M / 5 M / 10 M	
RST 5-713/...M		TPE/PLTC	2 M / 5 M / 10 M	
RST 5-794/...M		TPE/PLTC	2 M / 5 M / 10 M	
RST 8-627/...M	8	PVC	2 M / 5 M / 10 M	
RST 8-727/...M		TPE/PLTC	2 M / 5 M / 10 M	